

Datasheet


Item no. 1511450/ 1511473

V1_0617_01_en

Φ28 mm, USB2.0 Female A – Male A with 60cm cable

Item no.: 1511450 – Silver

1511473 – Black

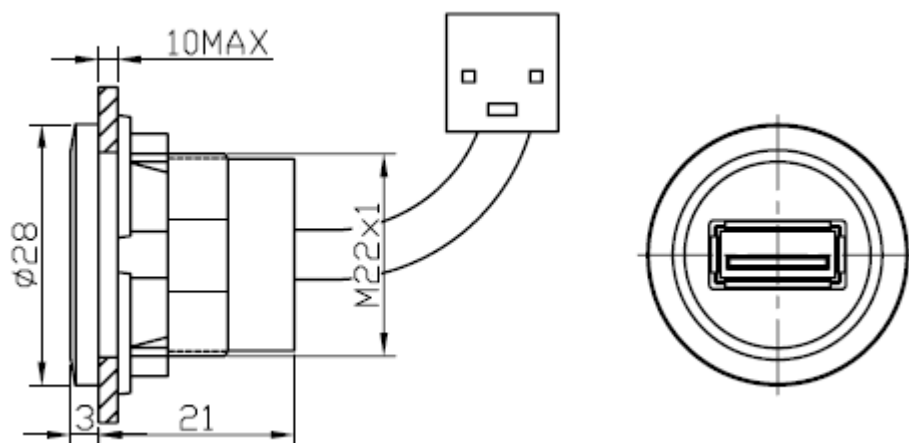

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification	USB2.0 Female A – Male A with 60cm cable
Mounting diameter	28 mm
Body material	PC
Operating and storage temperature.....	-20 to +55 °C
Operating and storage humidity.....	45 to 85 % RH
Panel thickness	1 ~ 10 mm
Transmission Speed	≥30MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.