


DATASHEET

Φ28 mm, USB2.0 Female A – Male A with 60cm cable
Item no.: 1511450 – Silver
1511473 – Black

Version 11/16

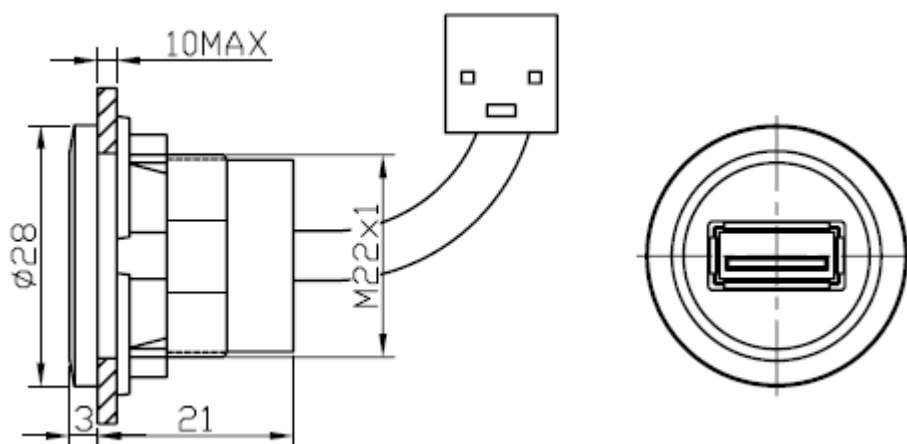

10MAX: means the panel thickness, the max thickness for the panel no more than 10mm.

Specification	USB2.0 Female A – Male A with 60cm cable
Mounting diameter	28 mm
Body material	PC
Operating and storage temperature.....	-20 to +55 °C
Operating and storage humidity.....	45 to 85 % RH
Panel thickness	1 ~ 10 mm
Transmission Speed	≥30MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represent the technical status at the time of printing.

© Copyright 2016 by Conrad Electronic SE.