



H-1/3AA300 Specifications

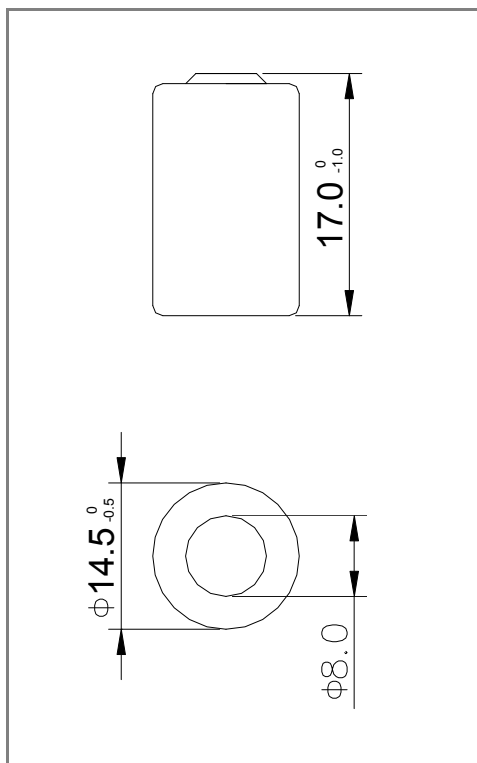


Nominal Capacity	300mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	< 60mΩ
Charge	
Standard Charge	30mA x 15h
Rapid Charge	300mA x 1.2h
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	14.5mm
Height	17.0mm
Weight	8 g
Operating Temperature	
Charge	0 ~ 45℃
Discharge	-20 ~ 60℃
Storage Temperature	
Within 1 month	-5 ~ 35℃
Within 6 months	0 ~ 35℃

Standard charge characteristics

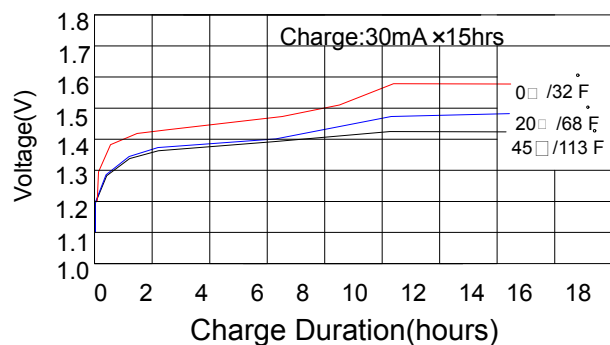

Rapid charge characteristics

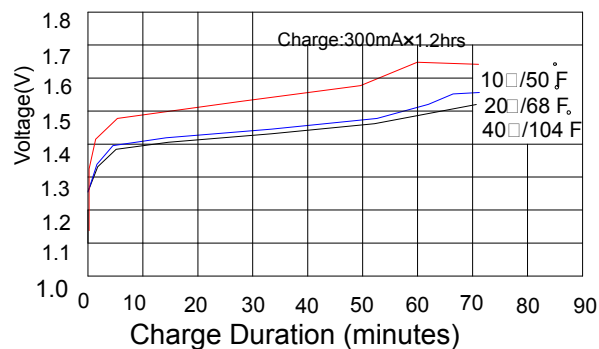

Discharge characteristics

