
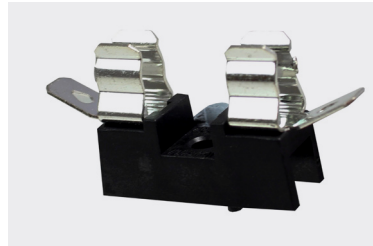



5x20mm chassis mounting 15A fuseholder

Product overview

- Centre hole fixing
- Anti-rotation spigots
- 5x20mm fuse
- High current rating
- Quick connect tabs
-  approved

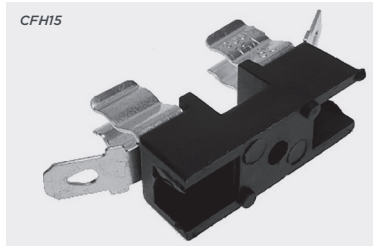

SPECIFICATION	
Rating	15A/250V
Contacts	High tensile phosphor bronze, 500MΩ
Moulding	Flame retardant PB
Dielectric strength	AC2000V
Insulation resistance	500MΩ

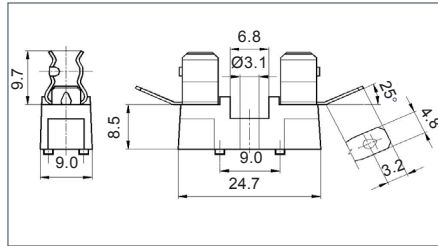


PART NO.	TYPE
CFH15	Chassis mounting 15A fuseholder



KEY FEATURES

Central fixing hole | 4.8mm Quick connect tab | 15A current rating

6.3x32mm chassis mounting fuseholder

Product overview

- Centre hole fixing
- 6.3x32mm fuse acceptance
- High current rating - 30A
- Quick connect tabs
-  approved

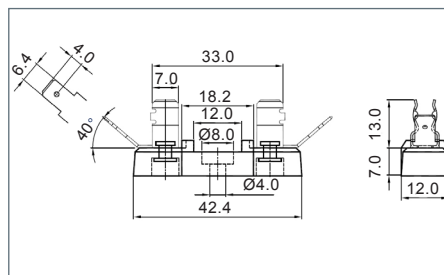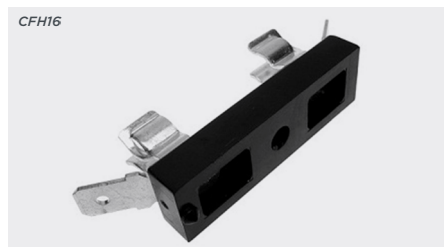

SPECIFICATION	
Rating	30A/ 300V
Contacts	Tinned nickel plated brass, 500MΩ
Moulding	UL94-V0 flame retardant phenolic thermosetting resin
Dielectric strength	AC2000V
Insulation resistance	500MΩ

PART NO.	TYPE
CFH16	Chassis mounting 30A fuseholder

KEY FEATURES

Central fixing hole | 6.4mm Quick connect tab | 30A current rating

