


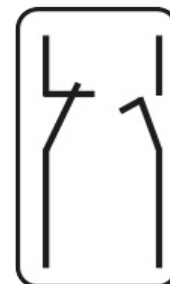

1NC & 1NO



Rapid Part Number: 28-4360
Europa Part Number: LBAC125RM2NO
 Specifications and dimensions

- Volt free contact auxiliary block
- 1NC and 1NO configuration
- NO contact is early make/late break



| Features | |
|---|--------------------|
| Height | 72mm |
| Width | 21mm |
| Depth | 47mm |
| Standard | IEC & EN 60947-3 |
| Rated operational voltage Ue IEC & EN | 500V |
| Rated operational current Ie AC15 240V | 6A |
| Rated operational current Ie AC15 415V | 4A |
| Maximum terminal capacity | 1.5mm ² |
| Recommended tightening torque terminal | 0.8Nm |
| Recommended tightening torque fixing screws | 0.3Nm |
| Suitable for | |
| LB boxed isolators 80A to 125A | |
| LBDI door interlock isolators 80A to 125A | |

ⓘ ALL PRODUCTS, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE.

Information provided in data sheets and/or specifications may vary from actual results in different applications and performance may vary over time. **All products must be installed according to manufacturers instructions.**

Europa House, Airport Way, Luton, Beds, LU2 9NH Tel: 01582 692 440 / Fax: 01582 692 450 e-mail: sales@europacomponents.com
 website: <http://www.europacomponents.com>