


RS Part Number: **28-4370**

Europa Part Number: **LBC404P**

Specifications and dimensions

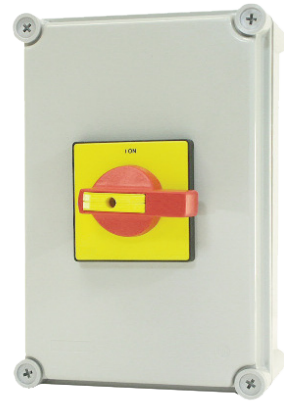

- Changeover Switch 4 Pole
- ABS plastic enclosure with lockable handle

Specifications	
Height	280mm
Width	190mm
Depth	130mm
Depth including switch	190mm
Degree of protection	IP65
Rated operational current Ie AC21A	63A
Rated operational current Ie AC22A	40A
Rated operational voltage Ue IEC & EN	690V
Rated operational power AC23A 380-440V	18.5kW
Rated operational power AC3 440V	15kW
Maximum gL fuse size IEC	62A
Rated fused short circuit capacity IEC	30kA
Normal operating temperature	-25°C to +40°C
Maximum cable capacity	25mm ²
Recommended tightening torque	2Nm
Number of possible auxilliary contacts	None

ⓘ ALL PRODUCTS, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE.

Information provided in data sheets and/or specifications may vary from actual results in different applications and performance may vary over time. **All products must be installed according to manufacturers instructions.**

Europa House, Airport Way, Luton, Beds, LU2 9NH Tel: 01582 692 440 / Fax: 01582 692 450 e-mail: sales@europacomponents.com
 website: <http://www.europacomponents.com>