


Rapid Part Number: **28-4404**  
 Europa Part Number: **EUBLM6B30**  
 Specifications and dimensions

- RCBO
- Din rail mounted for use on 230/240V AC

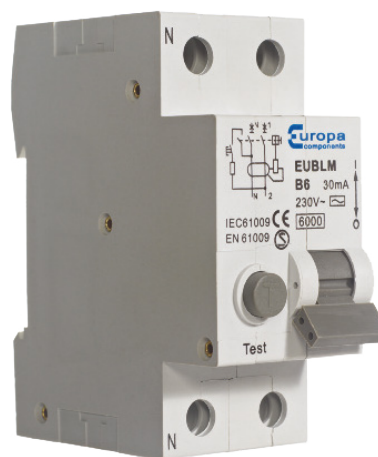

Dimensions	
Width	36mm
Height (overall)	82mm
Depth (overall)	76mm
Weight	0.21 Kg
Features	
Standard	EN61009
Degree of protection	IP20
Rated current In	6A
Rated Residual Operating Current IΔn	30mA
Tripping characteristic class	B
Rated voltage Ue	240V AC
Number of poles	2
Rated short circuit capacity Icn	6KA
Operating Temperature	-.5°C to +40°C
Degree of pollution	2
Maximum cable capacity	16mm <sup>2</sup>
Recommended tightening torque	2.0Nm
Related Products	
Suitable 4 way plastic enclosure	ECW4
Suitable 4 way metal enclosure	MEC4C

**ⓘ ALL PRODUCTS, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE.**

Information provided in data sheets and/or specifications may vary from actual results in different applications and performance may vary over time. **All products must be installed according to manufacturers instructions.**

Europa House, Airport Way, Luton, Beds, LU2 9NH Tel: 01582 692 440 / Fax: 01582 692 450 e-mail: sales@europacomponents.com  
 website: <http://www.europacomponents.com>