


Rapid Part Number: **28-4465**  
 Europa Part Number: **EUC1P40D**  
 Specifications and dimensions

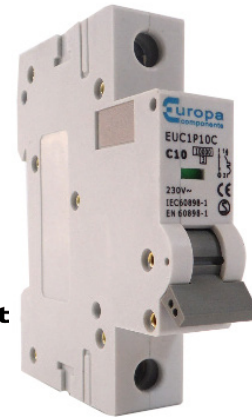

- Miniature Circuit Breakers
- Din rail mounted for use on 230/240V AC

Features	
Current Rating A	40
Width	17.5mm
Height (overall)	82mm
Depth (overall)	76mm
Weight	0.11Kg
Standard	EN60898
Degree of protection	IP20
Rated voltage Ue	240V AC
Number of poles	1
Rated impulse withstand voltage Uimp	4kV
Other amperages in the range	1, 2, 4, 6, 10, 16, 20, 25, 32, 50, 63
Rated short circuit capacity Icn	10KA
Characteristic curve	D
Instantaneous trip current	10 - 20 times full load current
Maximum cable capacity	25mm <sup>2</sup>
Recommended tightening torque	2.0Nm
Related Products	
Locking device	EUBLOCK
Padlock	EUBPADLOCK
Auxilliary switch	EUCA11

**ⓘ ALL PRODUCTS, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE.**

Information provided in data sheets and/or specifications may vary from actual results in different applications and performance may vary over time. **All products must be installed according to manufacturers instructions.**

Europa House, Airport Way, Luton, Beds, LU2 9NH Tel: 01582 692 440 / Fax: 01582 692 450 e-mail: sales@europacomponents.com  
 website: <http://www.europacomponents.com>