


Rapid Part Number: **28-4586**
 Europa Part Number: **TC1-D4011B7**
 Specifications and dimensions

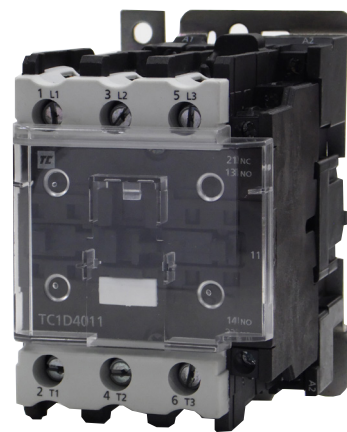

- 3 pole contactor with AC coil
- Double width (70mm) din rail or surface mount
- Normally open and normally closed auxiliary contacts

Features	
Height	127mm
Width	75mm
Depth	114mm
Weight	1.15Kg
Maximum standard power rating 415V AC3	22kW
Maximum switching current AC3	40A
Maximum switching current AC1	60A
Maximum rated voltage	690V
Standard	EN 60947-4-1
Mounting position from vertical plane	± 30°
Maximum operating rate cycles per hour	3600
Coil voltage	24V AC 50/60 Hz
Coil consumption inrush	245VA
Coil consumption sealed	26VA
Ambient temperature storage	, -50°C to +80°C
Ambient temperature operation	, -5°C to +55°C
Mechanical life - number of operations	6 x 10 ⁶
Maximum cable size for power contacts	25mm ²
Integral auxilliary contact rating Ith	10A
Related Products	
Plastic enclosure	PB65C
Metal enclosure	STB252515
Thermal overload range	TR2
Front mount auxilliary block range	TA1
Side mount auxilliary block range	TA8
Front mount timer range	TA2/TA3
Mechanical interlock	LA9-D50978
Spare coil	TX1D6B7

ⓘ ALL PRODUCTS, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE.

Information provided in data sheets and/or specifications may vary from actual results in different applications and performance may vary over time. **All products must be installed according to manufacturers instructions.**

Europa House, Airport Way, Luton, Beds, LU2 9NH Tel: 01582 692 440 / Fax: 01582 692 450 e-mail: sales@europacomponents.com
 website: <http://www.europacomponents.com>