




## LEDtec LED Indicators



IP65 LED indicators utilise multi-chip technology to provide bright even colour in red, blue, yellow, white and green. An aesthetically appealing design featuring single back of panel lock-nut fixing and screw clamp terminals for easy mounting and connection.

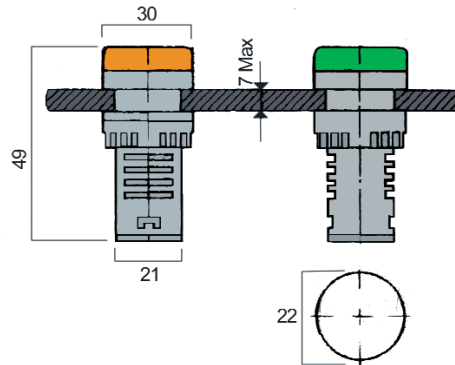

### Technical data:

Temperature Range	-25°C to +55°C
Relative Humidity	<=98%
Insulation Withstand	2.5Kv (ac) 1 min.
Insulation Resistance	≥2MΩ
Operating Voltage Range	Vn +20%
Operational Life	30,000 hrs
Brightness	>=60cd/m <sup>2</sup>
IP Rating	IP65
Frequency	AC 50-60Hz
Carton Quantity	10 pcs

### LEDtec Ordering Scheme:

