


PCB - BC 107,6/40 U11 HBUS DEV-PCB - 2202544

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)


Printed-circuit board for the BC 107,6 DEV-KIT

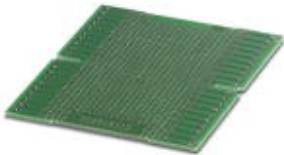

Why buy this product

- Hole matrix PCB for self-assembly
- Assembly area approx. 7,650 mm²
- Hole matrix dimension: 2.54 mm

Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 142418
Weight per Piece (excluding packing)	32.5 g
Custom tariff number	85340011
Country of origin	Germany
Product key	ACHIBB

Technical data

General

Housing type	Component housing
Housing material	FR 4-21
Color	green

Ambient conditions

Ambient temperature (operation)	110 °C (depending on power dissipation)
---------------------------------	---

Dimensions

Pitch	2.54 mm
	5 mm

Technical data

Flammability rating according to UL 94	V0
--	----

PCB - BC 107,6/40 U11 HBUS DEV-PCB - 2202544

Classifications

eCl@ss

eCl@ss 5.1	27379201
------------	----------

ETIM

ETIM 4.0	EC002498
ETIM 5.0	EC001031

Accessories

Additional products

Electronic housing - BC 107,6 DEV-KIT KMGY - 2202525



DEV-KIT BC 107,6: contains 1 x BC 107,6 housing and PCB terminal blocks (MKDS), supplied in individual parts

Plug - HBUS 107,6-16P-1S DEV-KIT BK - 2202545

Bus connector to connect BC modules on the DIN rail; suitable for BC DEV-KITS, contains HBUS 107,6 and pin strip

