

ARCA 403015

FIBOX
Enclosing innovations



Sample image

Order symbol: ARCA 403015

Product nbr: 8120006

Description: Cabinet. PC


Remarks: Grey cover. 2-point locking, hinges on the long side

Including: Cabinet base, door with PUR gasket, mounting plate, screws for mounting plate, 3mm double bit lock(s) with key, 5 versions with swinghandle 2-point locking system. Door guide included.

EAN: 6418074079176

El. number:

- Finland: 3423051
- Denmark: 8212091045
- Sweden: 2500112

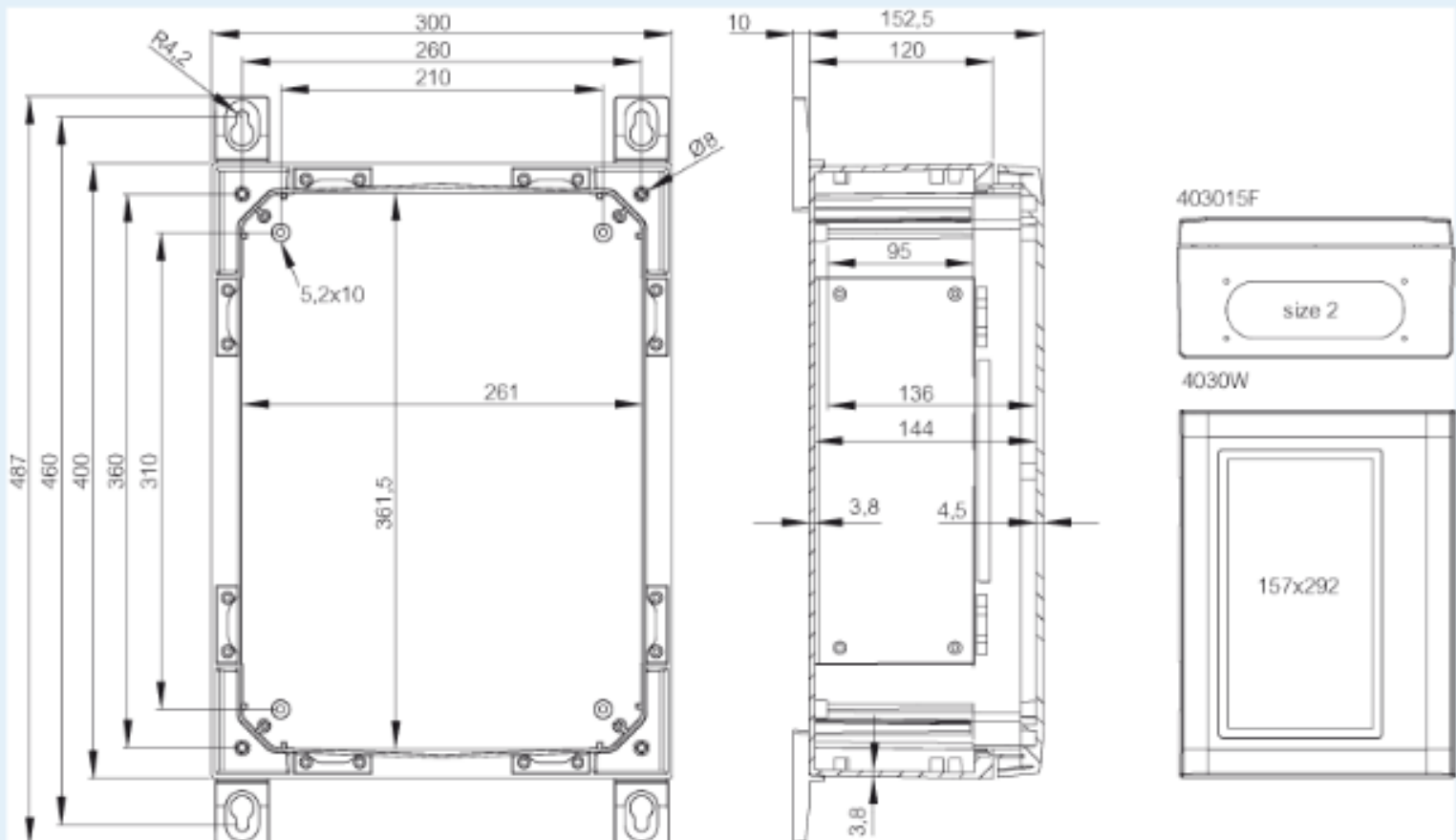

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm: | 400 | 300 | 150 |
| inch: | 15.75 | 11.81 | 6.22 |

Materials:

| | |
|------------------|----------------------|
| Material: | Polycarbonate |
| Base colour: | RAL 7035 -light grey |
| Cover colour: | RAL 7035 -light grey |
| Gasket material: | Polyurethane |

Temperatures:

| | |
|------------------------------|-------------|
| Temperature °C (short term): | -40 ... 120 |
| Temperature °C (continuous): | -40 ... 80 |
| Temperature °F (short term): | -40 ... 250 |
| Temperature °F (continuous): | -40 ... 175 |

Accessories:

| | |
|-----------------|--|
| DRS ARCA 403015 | DIN rail frame set (385 x 285 x 35) |
| SBK ARCA 30 | Support bar kit (235 x 40 x 30) |
| RCS ARCA 4030 | Rain canopy set for size 4030 (20 x 300 x 30) |
| SBK ARCA 40 | Support bar kit (340 x 40 x 30) |
| IDS ARCA 4030 | Inner door set (385 x 285 x 35) |
| PMK ARCA 30 | PoleMounting kit. for pole \varnothing 100-300mm (385 x 285 x 35) |
| DSP ARCA VLS | Door stopper ARCA. vertical. left. small |
| MPMP ARCA 4030 | Mounting plate multiperforated (350x250x2 mm - \varnothing 3.6 mm) (350 x 250 x 2) |
| DSP ARCA VRS | Door stopper ARCA. vertical. right. small |
| MPS ARCA 4030 | Mounting plate (350x250x2 mm) (350 x 250 x 2) |
| MPP ARCA 4030 | Mounting plate perforated (350x250x2 mm - 26x11 mm) (350 x 250 x 2) |
| MPX ARCA 4030 | Mounting plate (350x250 mm) (350 x 250 x 5) |

Rating:

| | |
|--|--------------------------|
| Ingress protection (EN 60529): | IP66; |
| Impact Resistance (EN 62262): | IK10; |
| Electrical insulation: | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815): | 1 |
| UV resistance: | UL 508 |
| Flammability Rating: | UL 94 5VA |
| Glow Wire Test (IEC 695-2-1) °C: | 960 °C |
| NEMA Class | NEMA 1, 4, 4X, 12 and 13 |

Certificates:

Certificate FI 40467