

ARCA 403021

FIBOX
Enclosing innovations



Sample image

Order symbol: ARCA 403021

Product nbr: 8120007

Description: Cabinet, PC


Remarks: Grey cover. 2-point locking, hinges on the long side

Including: Cabinet base, door with PUR gasket, mounting plate, screws for mounting plate, 3mm double bit lock(s) with key, 5 versions with swinghandle 2-point locking system. Door guide included.

EAN: 6418074079183

El. number:

- Finland: 3423054
- Denmark: 8212091058
- Sweden: 2500114

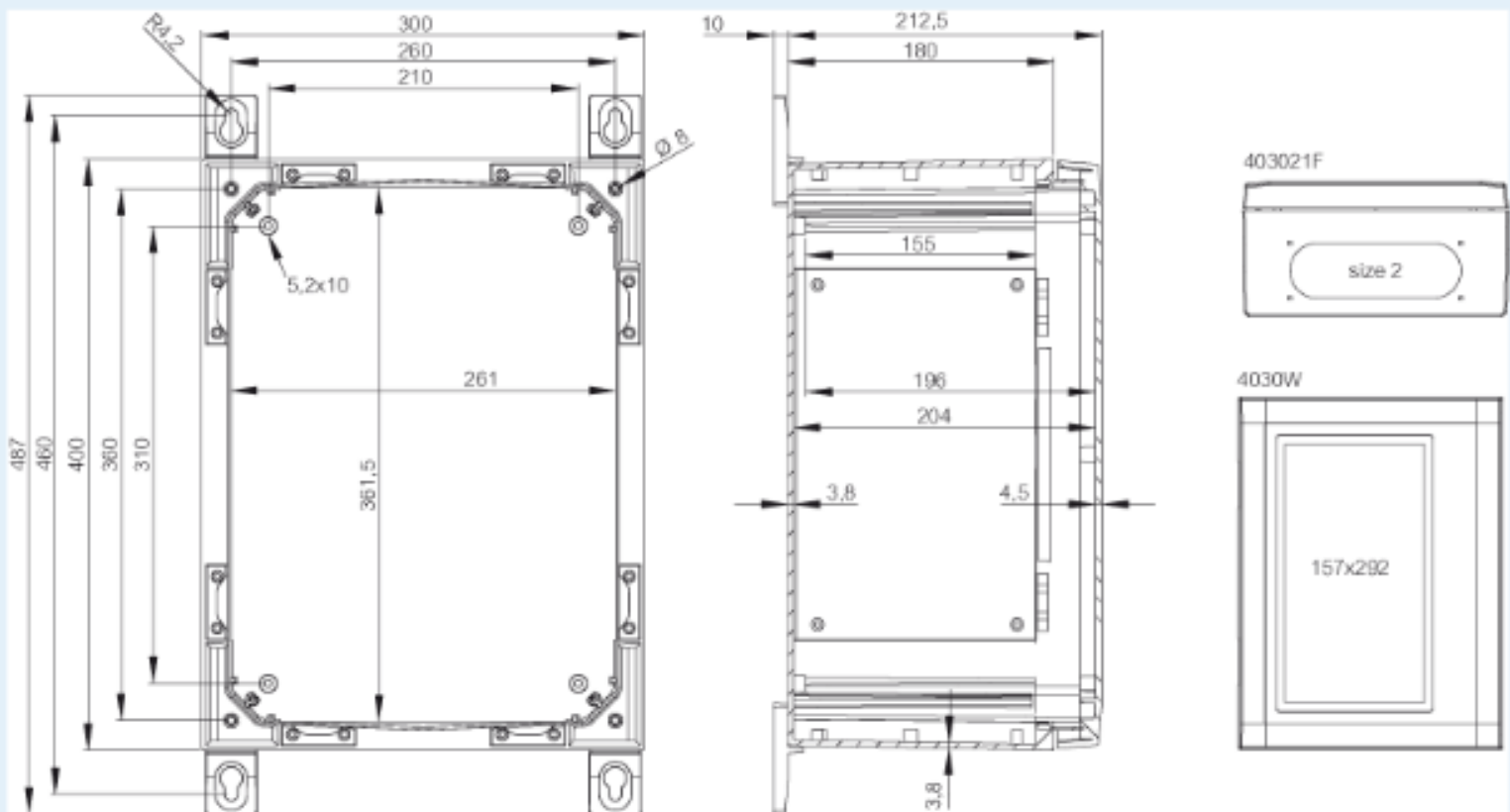

Dimensions:	Height	Width	Depth
mm:	400	300	210
inch:	15.75	11.81	8.27

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

DRS ARCA 403021	DIN rail frame set (385 x 285 x 35)
SBK ARCA 30	Support bar kit (235 x 40 x 30)
RCS ARCA 4030	Rain canopy set for size 4030 (20 x 300 x 30)
SBK ARCA 40	Support bar kit (340 x 40 x 30)
IDS ARCA 4030	Inner door set (385 x 285 x 35)
PMK ARCA 30	PoleMounting kit. for pole \varnothing 100-300mm (385 x 285 x 35)
DSP ARCA VLS	Door stopper ARCA. vertical. left. small
MPMP ARCA 4030	Mounting plate multiperforated (350x250x2 mm - \varnothing 3.6 mm) (350 x 250 x 2)
DSP ARCA VRS	Door stopper ARCA. vertical. right. small
MPS ARCA 4030	Mounting plate (350x250x2 mm) (350 x 250 x 2)
MPP ARCA 4030	Mounting plate perforated (350x250x2 mm - 26x11 mm) (350 x 250 x 2)
MPX ARCA 4030	Mounting plate (350x250 mm) (350 x 250 x 5)

Rating:

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

Certificates:

Certificate FI 40467