

ARCA 608030

FIBOX
Enclosing innovations



Sample image

Order symbol: ARCA 608030

Product nbr: 8120029

Description: Cabinet, PC


Remarks: Grey cover. 2-point locking, hinges on the short side

Including: Cabinet base, door with PUR gasket, mounting plate, screws for mounting plate, 3mm double bit lock(s) with key, 5 versions with swinghandle 2-point locking system. Door guide included.

EAN: 6418074085160

El. number:

- Finland: 3424064
- Denmark: 8212095368
- Sweden: 2500121

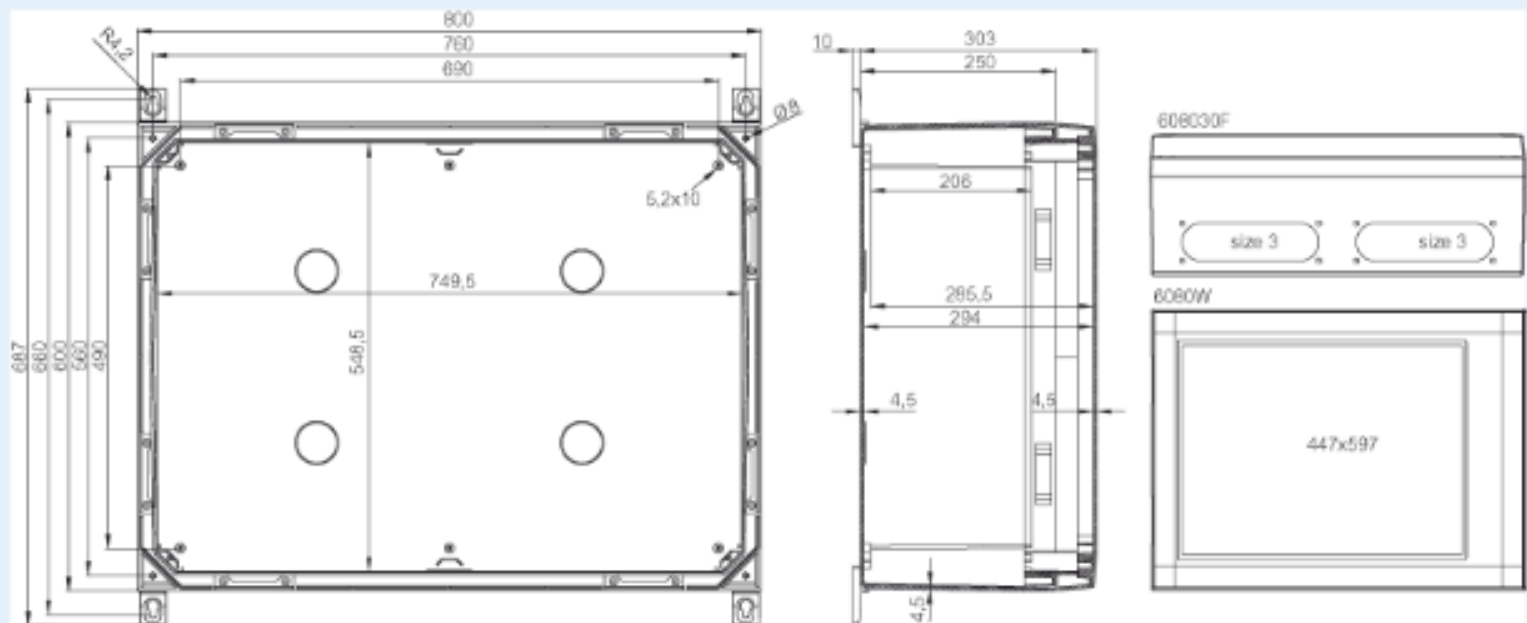

Dimensions:	Height	Width	Depth
mm:	600	800	300
inch:	26.62	31.5	12.2

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

DRS ARCA 608030	DIN rail frame set (785 x 585 x 35)
RCS ARCA 6080	Rain canopy set for size 6080 (20 x 800 x 30)
DSP ARCA RM	Door stopper ARCA, right, midsize 5070-8060
MPS ARCA 8060	Mounting plate (730x530x2 mm) (730 x 530 x 2)
DSP ARCA LM	Door stopper ARCA, left, midsize 5070-8060
IDS ARCA 6080	Inner door set (585 x 785 x 35)
MPMP ARCA 8060	Mounting plate multiperforated (730x530x2 mm - \varnothing 3.6 mm) (730 x 530 x 2)
SBK ARCA 80	Support bar kit (715 x 50 x 30)
SBK ARCA 60	Support bar kit (535 x 40 x 30)
PMK ARCA 80	PoleMounting kit, for pole \varnothing 100-300mm (785 x 585 x 35)
MPP ARCA 6080	Mounting plate perforated (730x530x2 mm - 26x11 mm) (530 x 730 x 2)
MPX ARCA 8060	Mounting plate (730x530 mm) (730 x 530 x 5)

Rating:

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

Certificates:

Certificate FI 40467