

DRS ARCA 203015

FIBOX
Enclosing innovations



Sample image

Order symbol: DRS ARCA 203015

Product nbr: 8120791

Description: DIN rail frame set


Remarks: 1 row x 11 modules, for size 200x300x150

Including:

EAN: 6418074082992

El. number:

- Finland: 3423882
- Denmark: 8212094848
- Sweden: 2500196

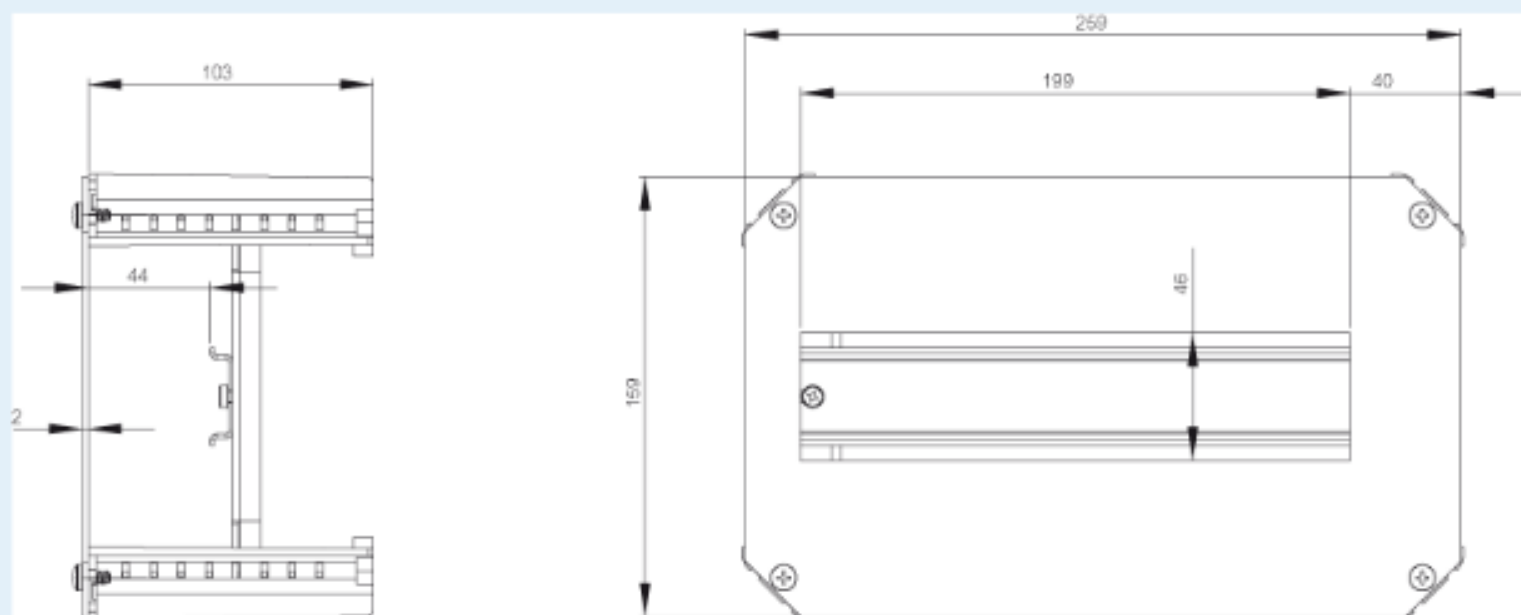

Dimensions:	Height	Width	Depth
mm:	285	185	35
inch:	11.22	7.28	1.38

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

Certificates: