

# DRS ARCA 304015

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** DRS ARCA 304015

**Product nbr:** 8120793

**Description:** DIN rail frame set



**Remarks:** 1 row x 16 modules. for size 300x400x150

**EAN:** 6418074083012

**El. number:**

- Finland: 3423884
- Denmark: 8212094864
- Sweden: 2500197

**Including:**

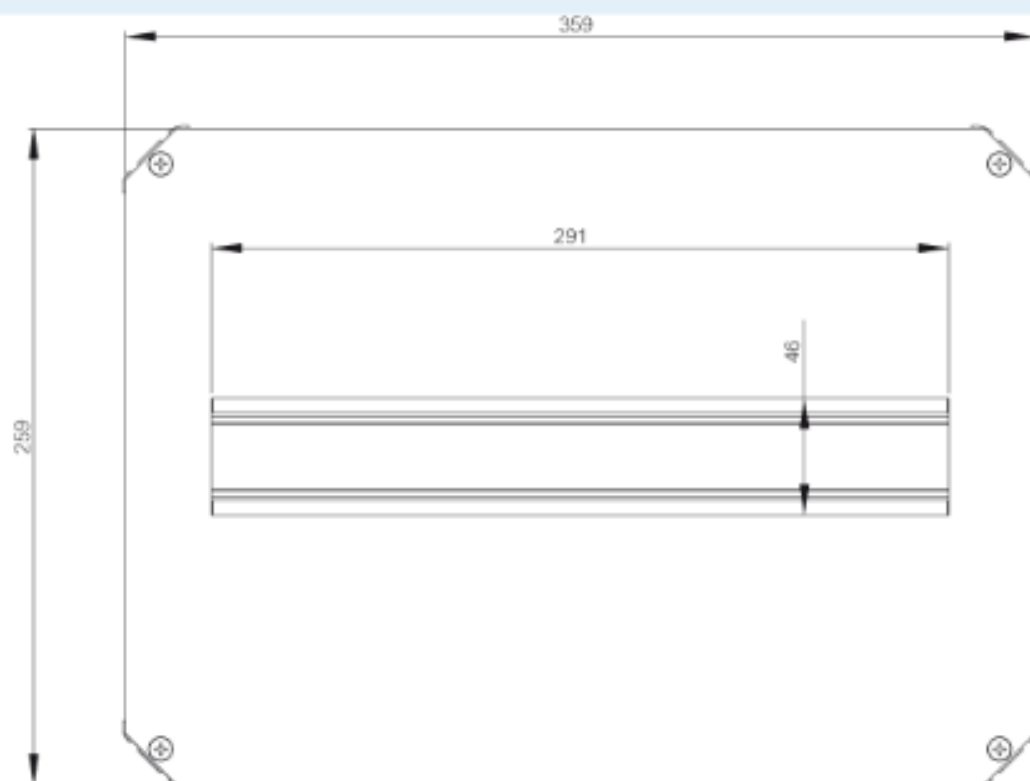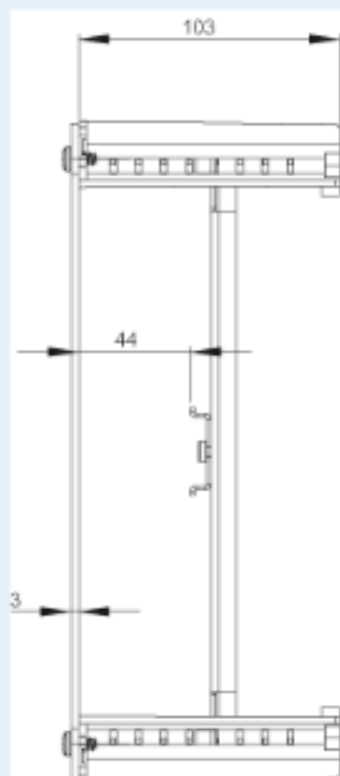

Dimensions:	Length	Width	Height
mm:		285	385
inch:		11.22	15.16

#### Materials:

Material:

Base colour:

Cover colour:

Gasket material:

#### Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

#### Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:

NEMA Class

#### Certificates: