


# IDS ARCA 3020

**FIBOX**  
Enclosing innovations

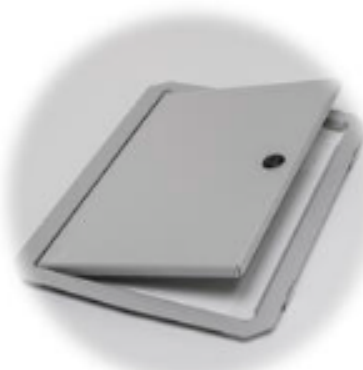

Sample image

**Order symbol:** IDS ARCA 3020

**Product nbr:** 8120711

**Description:** Inner door set



**Remarks:** Galvanized steel. RAL 7035. for size 300x200x150


**EAN:** 6418074082367

**El. number:**

- Finland: 3423684
- Denmark: 8212094217
- Sweden: 2500171

**Including:**

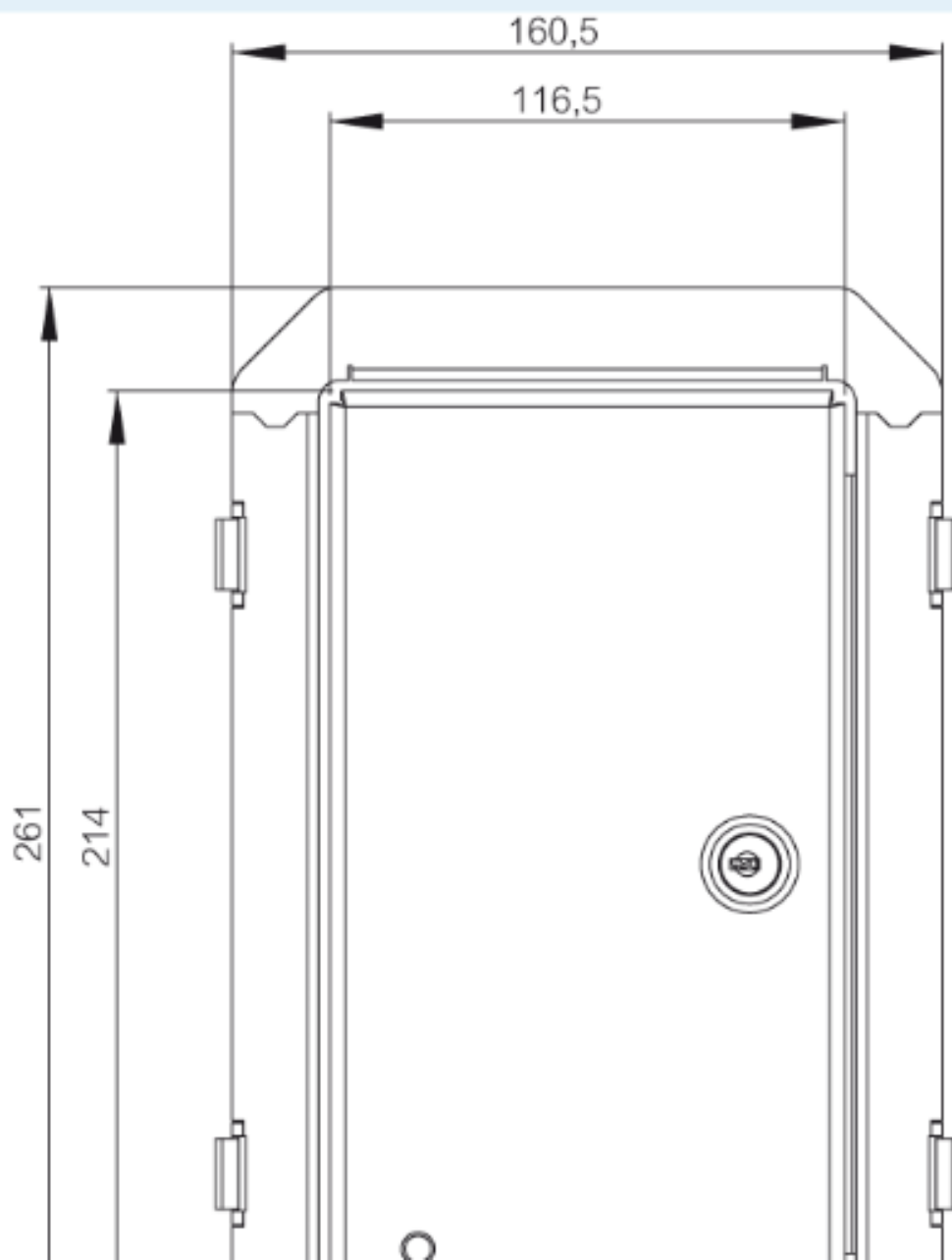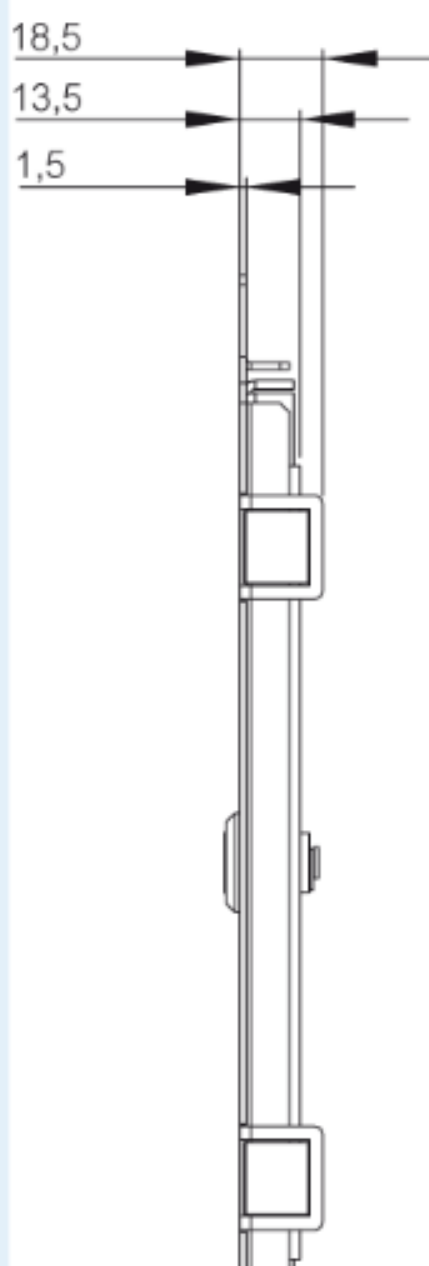

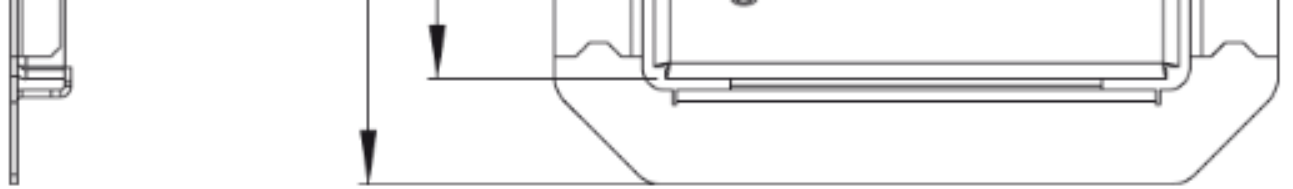

Dimensions:	Length	Width	Height
mm:		185	285
inch:		7.28	11.22

#### Materials:

Material: \_\_\_\_\_

Base colour: \_\_\_\_\_

Cover colour: \_\_\_\_\_

Gasket material: \_\_\_\_\_

#### Temperatures:

Temperature °C (short term): \_\_\_\_\_

Temperature °C (continuous): \_\_\_\_\_

Temperature °F (short term): \_\_\_\_\_

Temperature °F (continuous): \_\_\_\_\_

#### Rating:

Ingress protection (EN 60529): \_\_\_\_\_

Impact Resistance (EN 62262): \_\_\_\_\_

Electrical insulation: \_\_\_\_\_ Not insulated

Halogen free (DIN/VDE 0472, Part 815): \_\_\_\_\_ 0

UV resistance: \_\_\_\_\_ -

Flammability Rating: \_\_\_\_\_

Glow Wire Test (IEC 695-2-1) °C: \_\_\_\_\_

NEMA Class \_\_\_\_\_

#### Certificates: