

MPMP ARCA 3020

FIBOX
Enclosing innovations



Sample image

Order symbol: MPMP ARCA 3020

EAN: 6418074089472

Product nbr: 8120920


El. number:

Description: Mounting plate
multiperforated (250x150x2 mm -
ø3.6 mm)

- Finland:
- Denmark:
- Sweden:

Remarks: Galvanized steel. for size
300x200x150

Including:

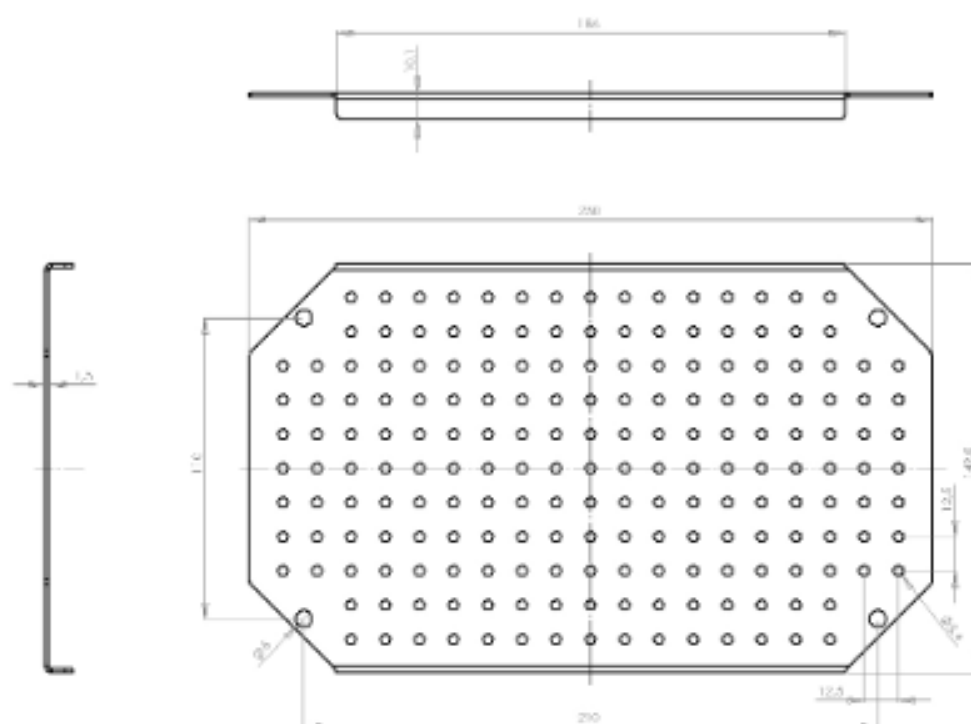

Dimensions:	Length	Width	Height
mm:		150	250
inch:		0	0

Materials:

Material: _____

Base colour: _____

Cover colour: _____

Gasket material: _____

Temperatures:

Temperature °C (short term): _____

Temperature °C (continuous): _____

Temperature °F (short term): _____

Temperature °F (continuous): _____

Rating:

Ingress protection (EN 60529): _____

Impact Resistance (EN 62262): _____

Electrical insulation: _____ Not insulated

Halogen free (DIN/VDE 0472, Part 815): _____ 0

UV resistance: _____ -

Flammability Rating: _____

Glow Wire Test (IEC 695-2-1) °C: _____

NEMA Class _____

Certificates: