

# MPMP ARCA 5040

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** MPMP ARCA 5040

**EAN:** 6418074089519

**Product nbr:** 8120924


**El. number:**

**Description:** Mounting plate  
multiperforated (450x350x2 mm -  
ø3.6 mm)

- Finland:
- Denmark:
- Sweden:

**Remarks:** Galvanized steel. for size  
500x400x210

**Including:**

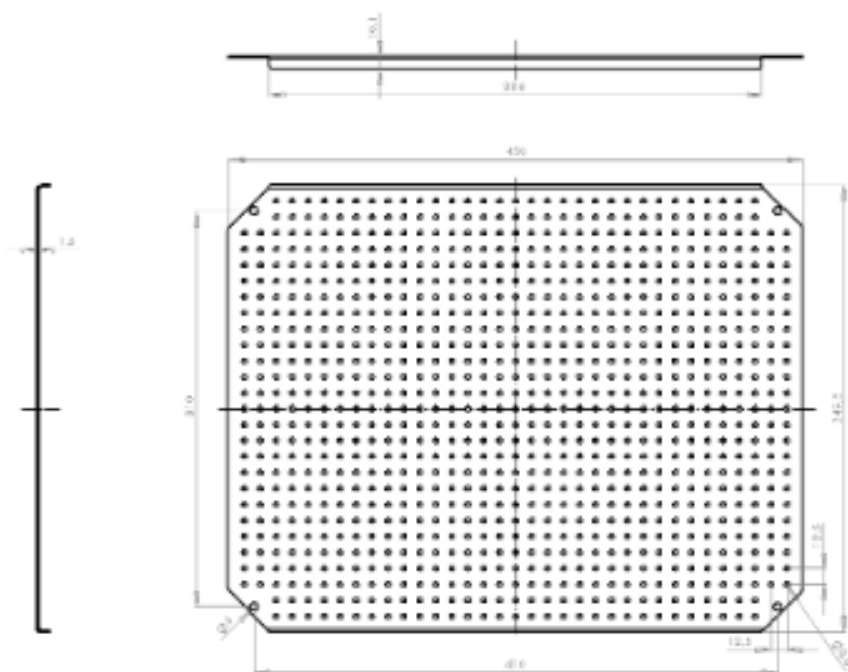

Dimensions:	Height	Width	Depth
-------------	--------	-------	-------

mm:	450	350	2
-----	-----	-----	---

inch:	0	0	0.08
-------	---	---	------

Materials:
------------

Material:
-----------

Base colour:
--------------

Cover colour:
---------------

Gasket material:
------------------

Temperatures:
---------------

Temperature °C (short term):
------------------------------

Temperature °C (continuous):
------------------------------

Temperature °F (short term):
------------------------------

Temperature °F (continuous):
------------------------------

Rating:
---------

Ingress protection (EN 60529):
--------------------------------

Impact Resistance (EN 62262):
-------------------------------

Electrical insulation:	Not insulated
------------------------	---------------

Halogen free (DIN/VDE 0472, Part 815):	0
--	---

UV resistance:	-
----------------	---

Flammability Rating:
----------------------

Glow Wire Test (IEC 695-2-1) °C:	C
----------------------------------	---

NEMA Class
------------

Certificates:
---------------