

MPMP ARCA 6040

FIBOX
Enclosing innovations



Sample image

Order symbol: MPMP ARCA 6040

EAN: 6418074089526

Product nbr: 8120925


El. number:

Description: Mounting plate
multiperforated (550x350x2 mm -
ø3.6 mm)

- Finland:
- Denmark:
- Sweden:

Remarks: Galvanized steel, for size
600x400x210

Including:

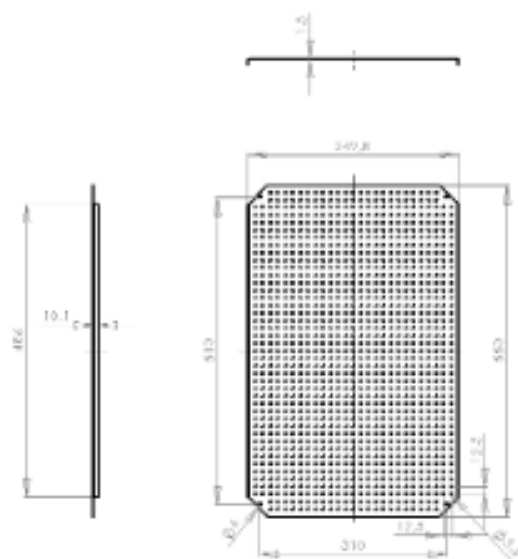

Dimensions:	Height	Width	Depth
-------------	--------	-------	-------

mm:	550	450	2
-----	-----	-----	---

inch:	0	0	0.08
-------	---	---	------

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation:	Not insulated
------------------------	---------------

Halogen free (DIN/VDE 0472, Part 815):	0
--	---

UV resistance:	-
----------------	---

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:	C
----------------------------------	---

NEMA Class

Certificates:
