

MPMP ARCA 7050

FIBOX
Enclosing innovations



Sample image

Order symbol: MPMP ARCA 7050

Product nbr: 8120927

Description: Mounting plate multiperforated (630x430x2 mm - \varnothing 3.6 mm)


Remarks: Galvanized steel. for size 700x500x300

Including:

EAN: 6418074089540

El. number:

- Finland:
- Denmark:
- Sweden:

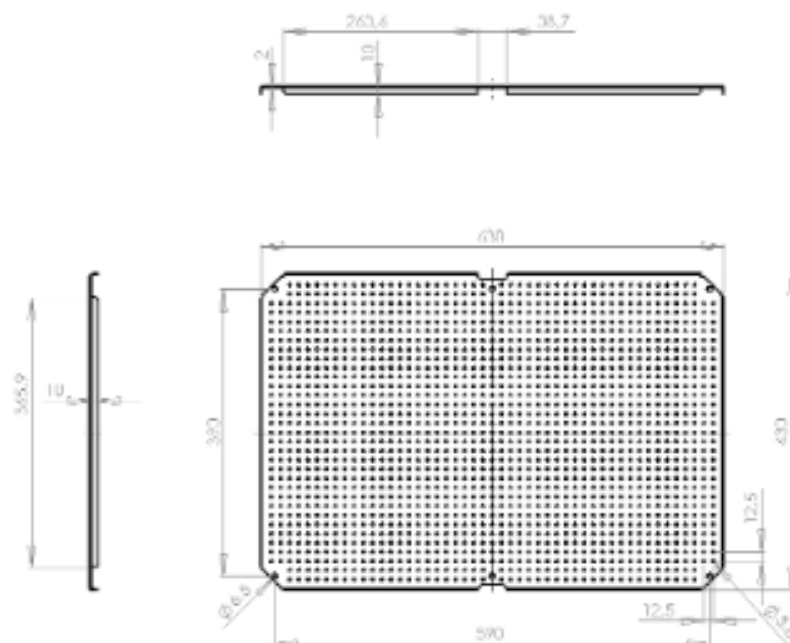

Dimensions:	Height	Width	Depth
-------------	--------	-------	-------

mm:	630	430	2
-----	-----	-----	---

inch:	0	0	0.08
-------	---	---	------

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation:	Not insulated
------------------------	---------------

Halogen free (DIN/VDE 0472, Part 815):	0
--	---

UV resistance:	-
----------------	---

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C:	C
----------------------------------	---

NEMA Class

Certificates:
