

MPMP ARCA 8060

FIBOX
Enclosing innovations



Sample image

Order symbol: MPMP ARCA 8060

Product nbr: 8120928

Description: Mounting plate multiperforated (730x530x2 mm - \varnothing 3.6 mm)


Remarks: Galvanized steel. for size 800x600x300

Including:

EAN: 6418074089557

El. number:

- Finland:
- Denmark:
- Sweden:

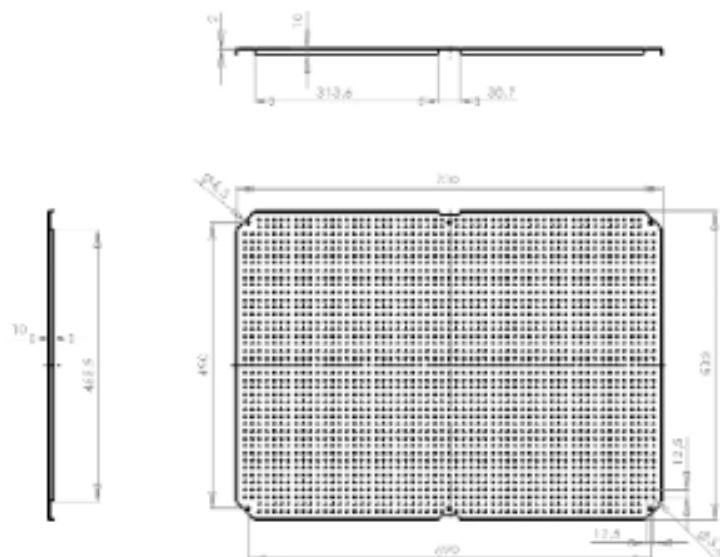

Dimensions:	Length	Width	Height
mm:		530	730
inch:		0	0

Materials:

Material: _____

Base colour: _____

Cover colour: _____

Gasket material: _____

Temperatures:

Temperature °C (short term): _____

Temperature °C (continuous): _____

Temperature °F (short term): _____

Temperature °F (continuous): _____

Rating:

Ingress protection (EN 60529): _____

Impact Resistance (EN 62262): _____

Electrical insulation: _____ Not insulated

Halogen free (DIN/VDE 0472, Part 815): _____ 0

UV resistance: _____ -

Flammability Rating: _____

Glow Wire Test (IEC 695-2-1) °C: _____

NEMA Class _____

Certificates: