


MPP ARCA 8060

FIBOX

Enclosing innovations

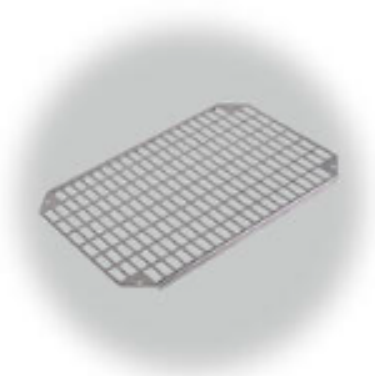

Sample image

Order symbol: MPP ARCA 8060

Product nbr: 8120759

Description: Mounting plate perforated (730x530x2 mm - 26x11 mm)


Remarks: Galvanized steel. for size 800x600x300

EAN: 6418074082800

El. number:

- Finland: 3423847
- Denmark:
- Sweden:

Including:

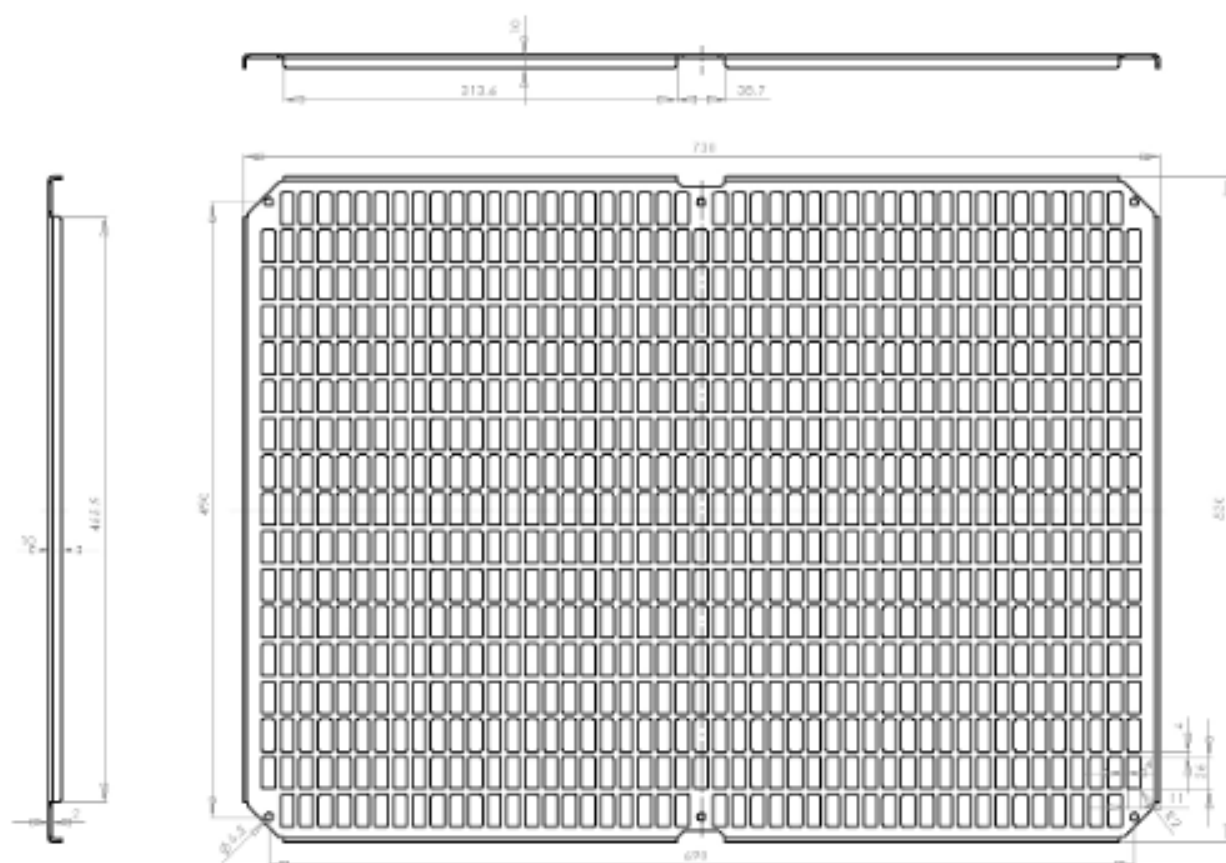

Dimensions:	Length	Width	Height
mm:		530	730
inch:		0	0

Materials:

Material: _____
Base colour: _____
Cover colour: _____
Gasket material: _____

Temperatures:

Temperature °C (short term): _____
Temperature °C (continuous): _____
Temperature °F (short term): _____
Temperature °F (continuous): _____

Rating:

Ingress protection (EN 60529): _____
Impact Resistance (EN 62262): _____
Electrical insulation: _____ Not insulated
Halogen free (DIN/VDE 0472, Part 815): _____ 0
UV resistance: _____ -
Flammability Rating: _____
Glow Wire Test (IEC 695-2-1) °C: _____
NEMA Class _____

Certificates: