

# PC 080807

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** PC 080807

**Product nbr:** 7032560

**UL Code:** 7042560

**UL Name:** UL PC 080807

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

**EAN:** 6418074003614

**El. number:**

- Finland: 3423426
- Denmark: 8212002584
- Sweden: 2536109

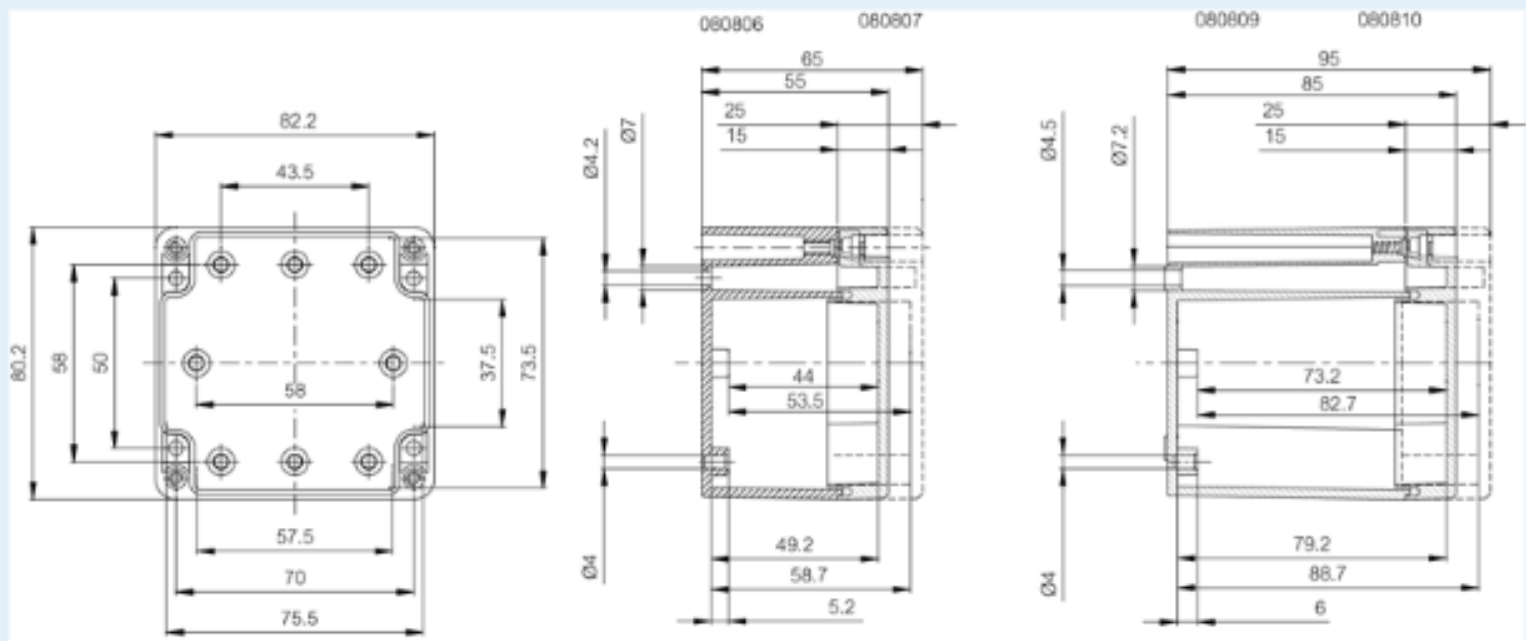

Dimensions:	Height	Width	Depth
mm:	80	82	65
inch:	3.15	3.23	2.56

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Accessories:

TF 28037	Mounting foot kit (4 pcs). for enclosures:
TM 0808	Back Panel. for enclosures: (56 x 71 x 1)
TH A	Gray plastic hinges (2 pcs)
TRM 0808	DIN-15 Mounting rail. for enclosures: (68 x 15 x 1)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

SGSFimko\_EURONORD