

PC 080809

FIBOX
Enclosing innovations



Sample image

Order symbol: PC 080809

Product nbr: 7032550

UL Code: 7042550

UL Name: UL PC 080809

Description: Enclosure. PC


Remarks: Opaque cover

Including: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

EAN: 6418074058324

El. number:

- Finland: 3435344
- Denmark: 8212002607
- Sweden: 2536110

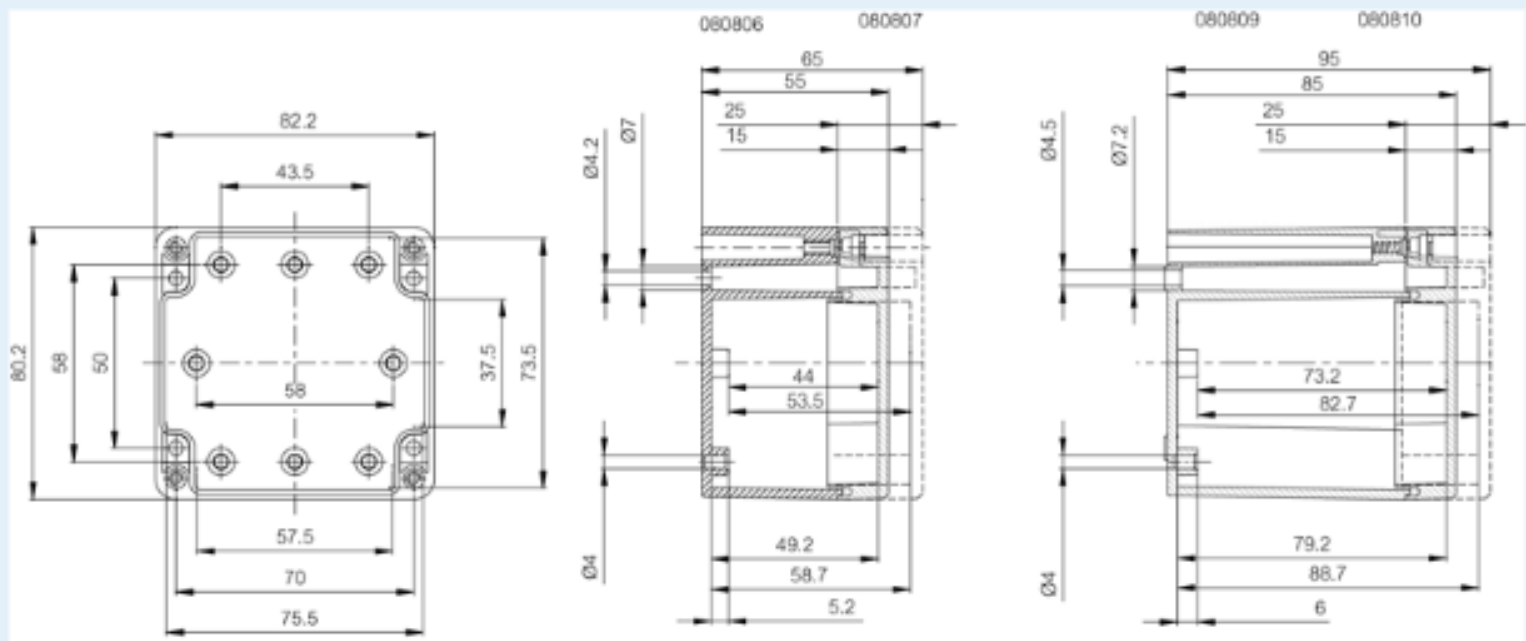

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm: | 80 | 82 | 85 |
| inch: | 3.15 | 3.23 | 3.35 |

Materials:

| | |
|------------------|----------------------|
| Material: | Polycarbonate |
| Base colour: | RAL 7035 -light grey |
| Cover colour: | RAL 7035 -light grey |
| Gasket material: | Polyurethane |

Temperatures:

| | |
|------------------------------|-------------|
| Temperature °C (short term): | -40 ... 120 |
| Temperature °C (continuous): | -40 ... 80 |
| Temperature °F (short term): | -40 ... 250 |
| Temperature °F (continuous): | -40 ... 175 |

Accessories:

| | |
|----------|--|
| TF 28037 | Mounting foot kit (4 pcs). for enclosures: |
| TM 0808 | Back Panel. for enclosures: (56 x 71 x 1) |
| TH A | Gray plastic hinges (2 pcs) |
| TRM 0808 | DIN-15 Mounting rail. for enclosures: (68 x 15 x 1) |

Rating:

| | |
|--|-------------------|
| Ingress protection (EN 60529): | IP66; IP67; |
| Impact Resistance (EN 62262): | IK07; IK08; |
| Electrical insulation: | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815): | 1 |
| UV resistance: | UL 508 |
| Flammability Rating: | UL 746C 5* |
| Glow Wire Test (IEC 695-2-1) °C: | 960 °C |
| NEMA Class | |

Certificates:

SGSFimko_EURONORD