

PC 122008

FIBOX
Enclosing innovations



Sample image

Order symbol: PC 122008

Product nbr: 7032760

UL Code: 7042760

UL Name: UL PC 122008

Description: Enclosure. PC


Remarks: Opaque cover

Including: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

EAN: 6418074003676

El. number:

- Finland: 3423438
- Denmark: B212002843
- Sweden: 2536125

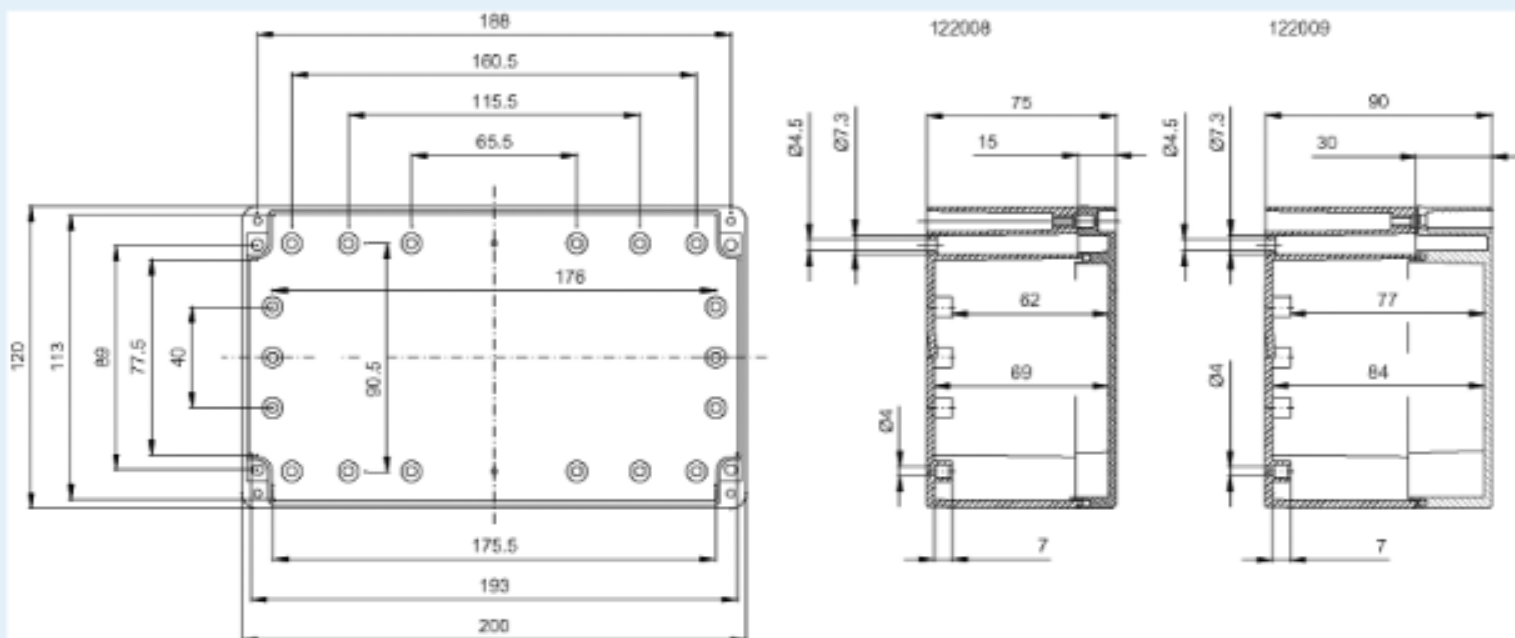

Dimensions:	Height	Width	Depth
mm:	120	200	75
inch:	4.72	7.87	2.95

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

MIV 10	DIN-35 Mounting rail, for enclosures: (100 x 35 x 1)
TF 28037	Mounting foot kit (4 pcs), for enclosures:
TRH 1220	DIN-15 Mounting rail, for enclosures: (186 x 35 x 1)
TM 1220	Back Panel, for enclosures: (111 x 174 x 2)
TH A	Gray plastic hinges (2 pcs)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

SGSFimko_EURONORD