

PC 150/50 LG

FIBOX

Enclosing innovations



Sample image

Order symbol: PC 150/50 LG

Product nbr: 6012314

UL Code: 6412314

UL Name: UL PC 150/50 LG

Description: Enclosure. PC



Remarks: Opaque cover

Including: Base with TPE gasket. screws for mounting plate/DIN-rail and cover with polyamide cover screws.

EAN: 6418074022141

El. number:

- Finland: 3420345
- Denmark: 8212022137
- Sweden: 2535542

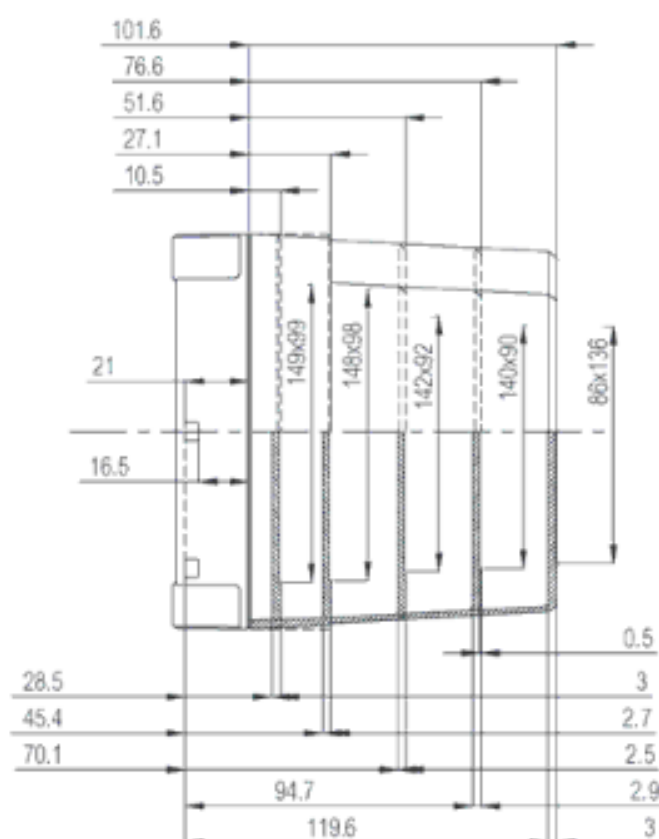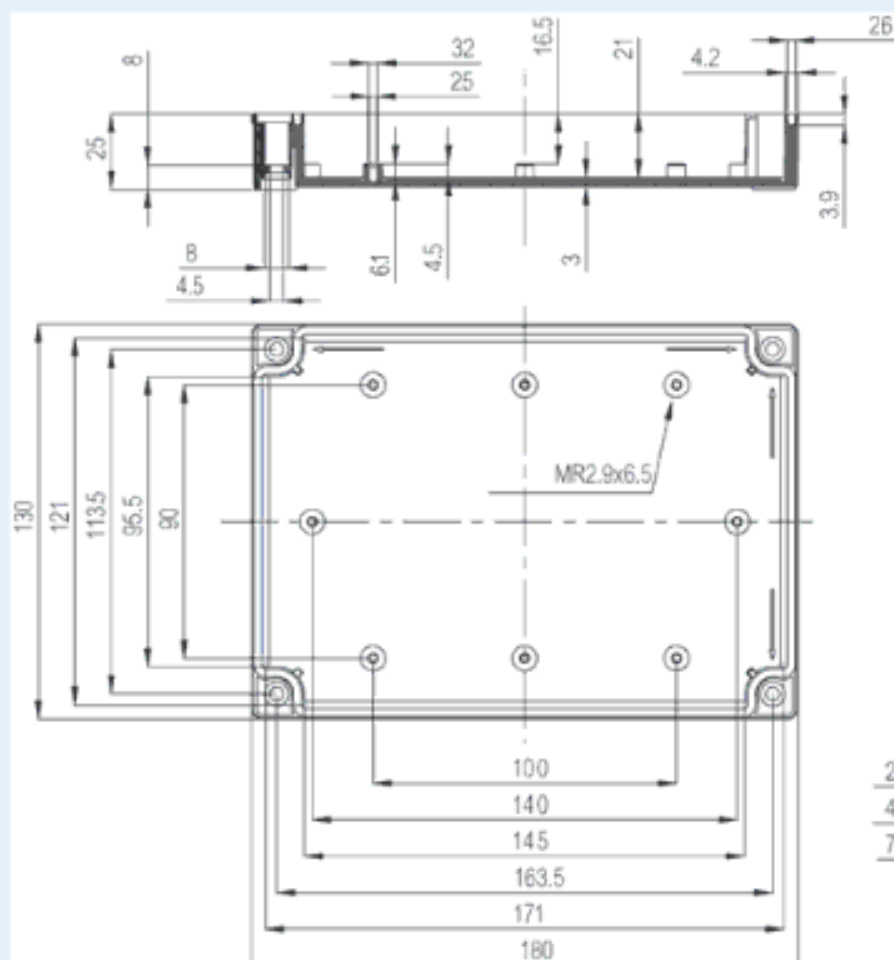

Dimensions:	Height	Width	Depth
-------------	--------	-------	-------

mm:	180	130	50
-----	-----	-----	----

inch:	7.09	5.12	1.97
-------	------	------	------

Materials:	
------------	--

Material:	Polycarbonate
-----------	---------------

Base colour:	RAL 7035 -light grey
--------------	----------------------

Cover colour:	RAL 7035 -light grey
---------------	----------------------

Gasket material:	Polyurethane
------------------	--------------

Temperatures:	
---------------	--

Temperature °C (short term):	-40 ... 120
------------------------------	-------------

Temperature °C (continuous):	-40 ... 80
------------------------------	------------

Temperature °F (short term):	-40 ... 250
------------------------------	-------------

Temperature °F (continuous):	-40 ... 175
------------------------------	-------------

Accessories:	
--------------	--

MIV 10	DIN-35 Mounting rail. for enclosures: (100 x 35 x 1)
--------	---

FP A 150/180	Front panel (Aluminum). for enclosures: (170 x 112 x 1)
--------------	--

HFP 180	Front panel hinge series
---------	--------------------------

MIV 150	Back Panel (Galvanized steel). for enclosures: (148 x 98 x 1)
---------	--

MIN 15	DIN-15 Mounting rail. for enclosures: (150 x 15 x 1)
--------	---

MIN 10	DIN-15 Mounting rail. for enclosures: (100 x 15 x 1)
--------	---

MIV 15	DIN-35 Mounting rail. for enclosures: (150 x 35 x 1)
--------	---

FP 22046	Mounting foot kit (4 pcs)
----------	---------------------------

Rating:	
---------	--

Ingress protection (EN 60529):	IP66; IP67;
--------------------------------	-------------

Impact Resistance (EN 62262):	IK08;
-------------------------------	-------

Electrical insulation:	Totally insulated
------------------------	-------------------

Halogen free (DIN/VDE 0472, Part 815):	1
--	---

UV resistance:	UL 508
----------------	--------

Flammability Rating:	UL 746C 5"
----------------------	------------

Glow Wire Test (IEC 695-2-1) °C:	960 °C
----------------------------------	--------

NEMA Class	
------------	--

Certificates:

Certificate FI 40847
