

PC 150/60 HG



Sample image

Order symbol : PC 150/60 HG

Product nr : 6011313

UL Name : UL PC 150/60 HG

Description : Enclosure, PC


Remarks : High base, grey cover

EAN : 6418074022172

El. number :

- Finland : 3420351
- Denmark : 8212022166
- Sweden : 2535551

Including : Base with TPE gasket. screws for mounting plate/DIN-rail and cover with polyamide cover screws.

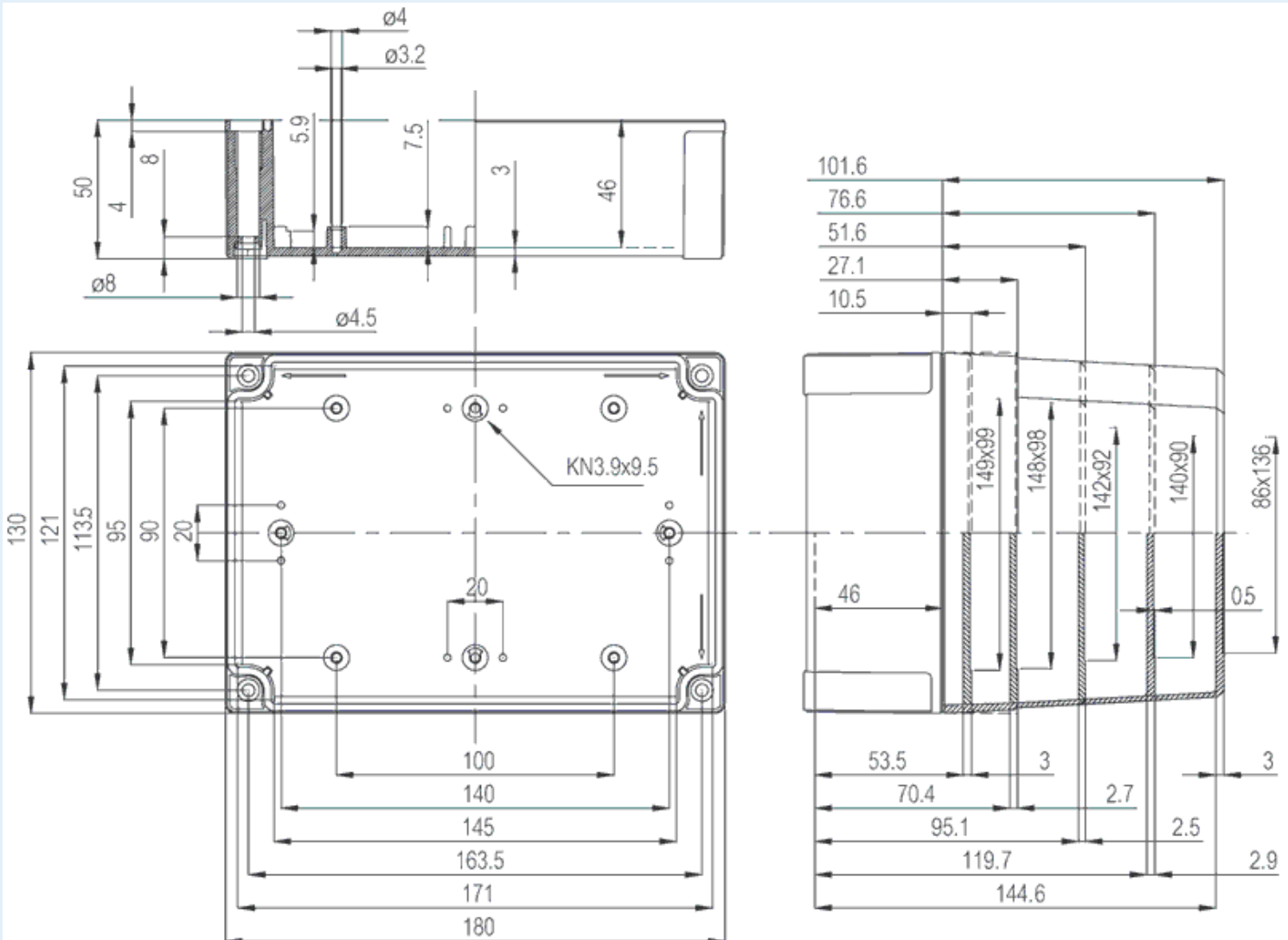

Dimensions :

| | Height | Width | Depth |
|--------|--------|-------|-------|
| mm : | 180 | 130 | 60 |
| inch : | 7.09 | 5.12 | 2.36 |

Materials :

| | |
|-------------------|----------------------|
| Material : | Polycarbonate |
| Base colour : | RAL_7035 |
| Cover colour : | RAL 7035 -light grey |
| Gasket material : | TPE |

Temperatures :

| | |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -40 ... 80 |
| Temperature °F (continuous) : | -40 ... 175 |

Accessories :

| | |
|------------------|---|
| MIV 10 | DIN-35 Mounting rail, for enclosures: (100 x 35 x 7.5) |
| FP A 150/ 180 | Front plate (Aluminium), for enclosures: (170 x 112 x 1) |
| HFP 180 | Front plate hinge series |
| MIV 150 | Mounting plate (Galvanized steel), for enclosures: (148 x 98 x 1.5) |
| MIN 15 | DIN-15 Mounting rail, for enclosures: (150 x 15 x 1) |
| MIN 10 | DIN-15 Mounting rail, for enclosures: |
| MIV 15 | DIN-35 Mounting rail, for enclosures: (150 x 35 x 7.5) |
| FP 22046 | Wall fastening lug (4 pcs) (35 x 16 x 10) |

Ratings :

| | |
|---|-------------------|
| Ingress protection (EN 60529): | IP66; IP67; |
| Impact Resistance (EN 62262): | IK08; |
| electrical_insulation : | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes |
| UV resistance : | UL 746C |
| Flammability Rating : | UL 94 V0 |
| Glow Wire Test (IEC 695-2-1) °C : | 960C |

Certificates :

Certificate FI 40847