

# PC 1919 13 G



Sample image

**Order symbol:** PC 1919 13 G

**Product nbr:** 5330359

UL Code: 5320359

UL Name: UL PC 1919 13 G

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**Including:** Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

**EAN:** 6418074005403

**El. number:**

- Finland: 3423701
- Denmark:
- Sweden: 2539406

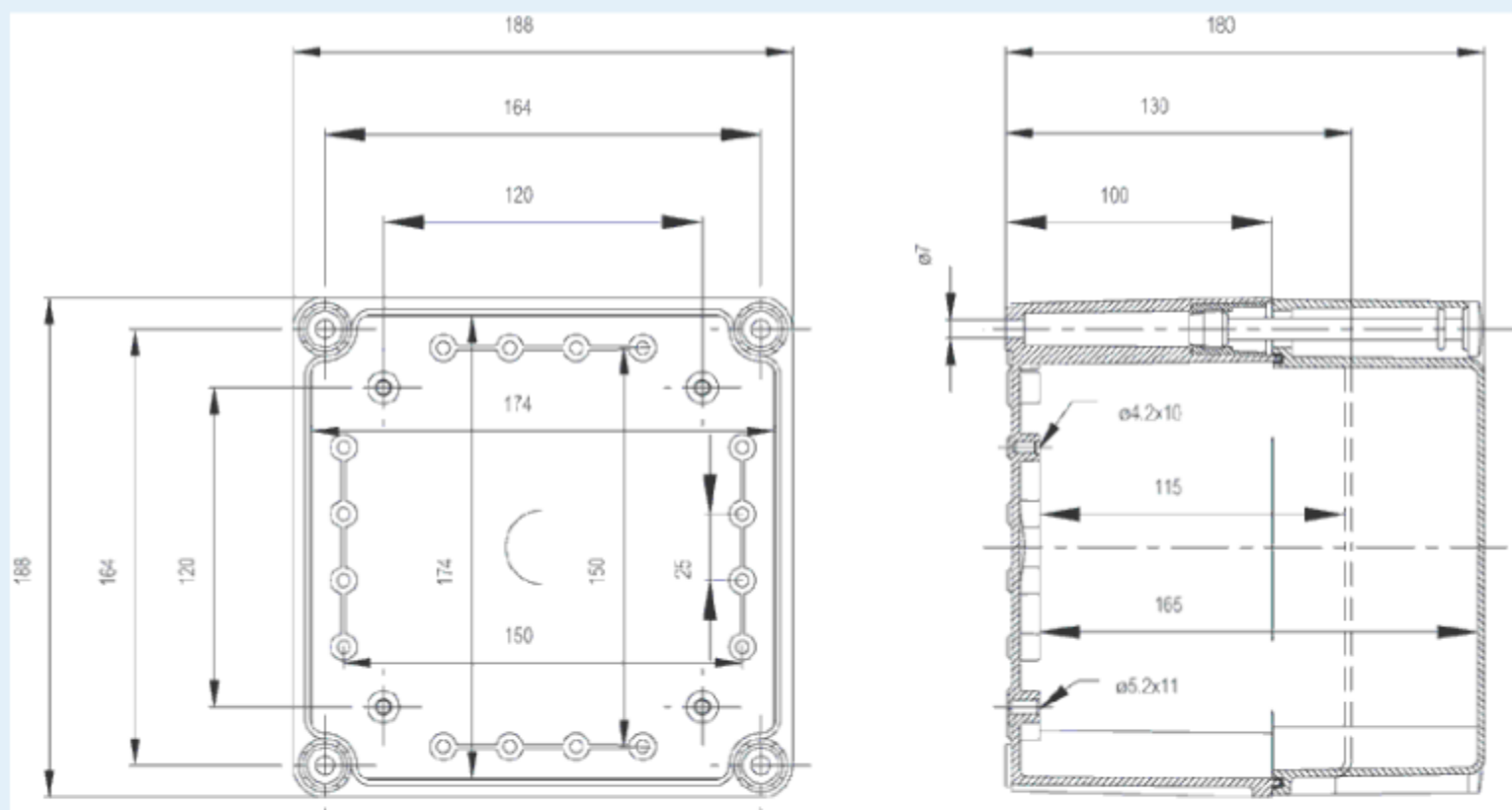

Dimensions:      Height      Width      Depth

Accessories:

mm:	190	190	130
inch:			

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

EKHVT	Back Panel, for enclosures: (148 x 148 x 1)
EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

Certificate NCS FI 30308