

PC 203615

FIBOX


Enclosing innovations



Sample image

Order symbol: PC 203615**Product nbr:** 7032790**UL Code:** 7042790**UL Name:** UL PC 203615**Description:** Enclosure. PC**Remarks:** Opaque cover**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.**EAN:** 6418074058508**El. number:**

- Finland: 3435380
- Denmark: 8212003020
- Sweden: 2536134

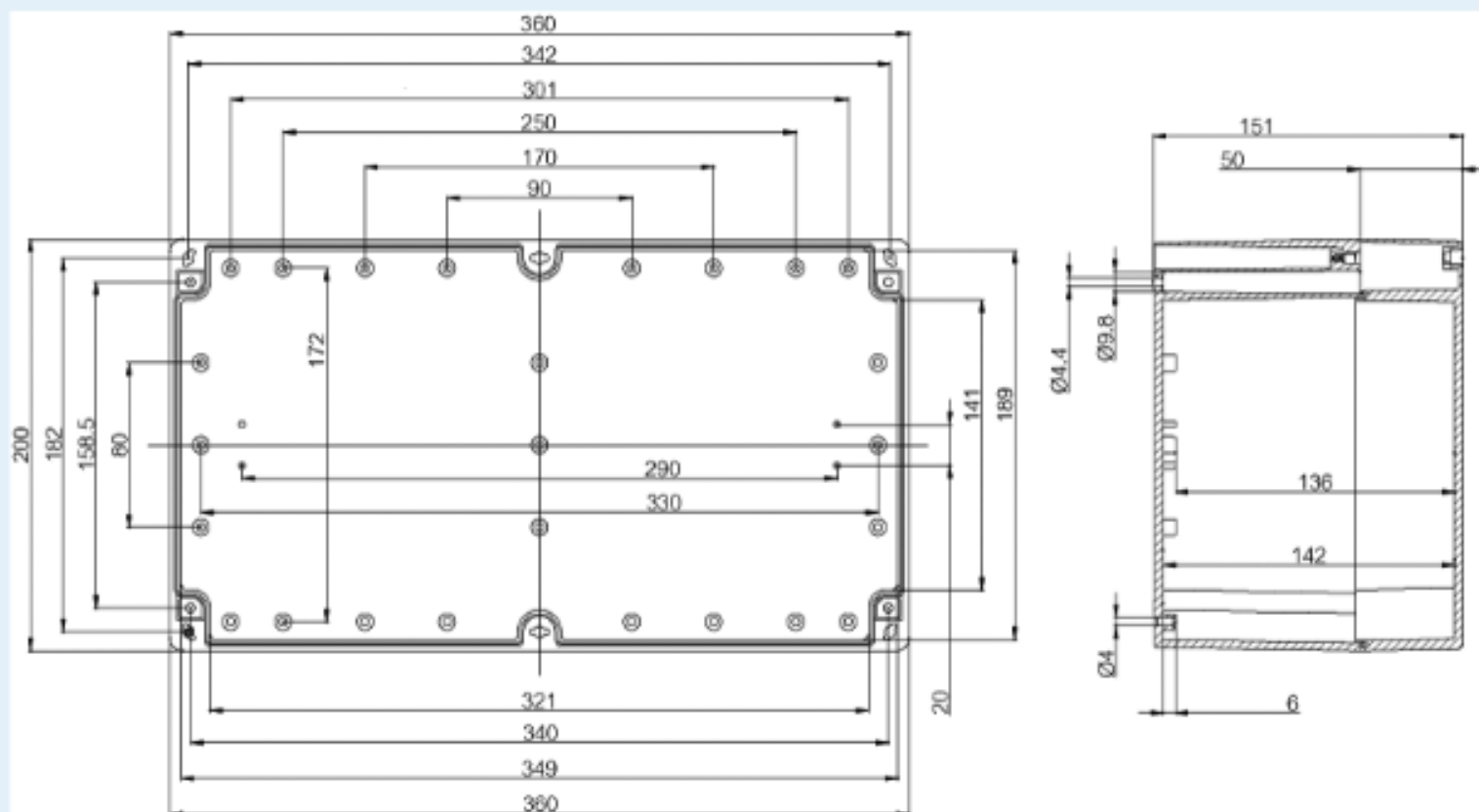

Dimensions:	Height	Width	Depth
mm:	200	360	150
inch:	7.87	14.17	5.91

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

TF 28037	Mounting foot kit (4 pcs). for enclosures:
TM 2036	Back Panel. for enclosures: (318 x 186 x 1)
TH A	Gray plastic hinges (2 pcs)
TRH 2036	DIN-15 Mounting rail. for enclosures: (35 x 340 x 1)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

SGSFimko_EURONORD