

# PC 233011



Sample image

**Order symbol:** PC 233011

**Product nbr:** 7032890

UL Code: 7042890

UL Name: UL PC 233011

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

**EAN:** 6418074003713

**El. number:**

- Finland: 3423446
- Denmark: 8212003046
- Sweden: 2536137

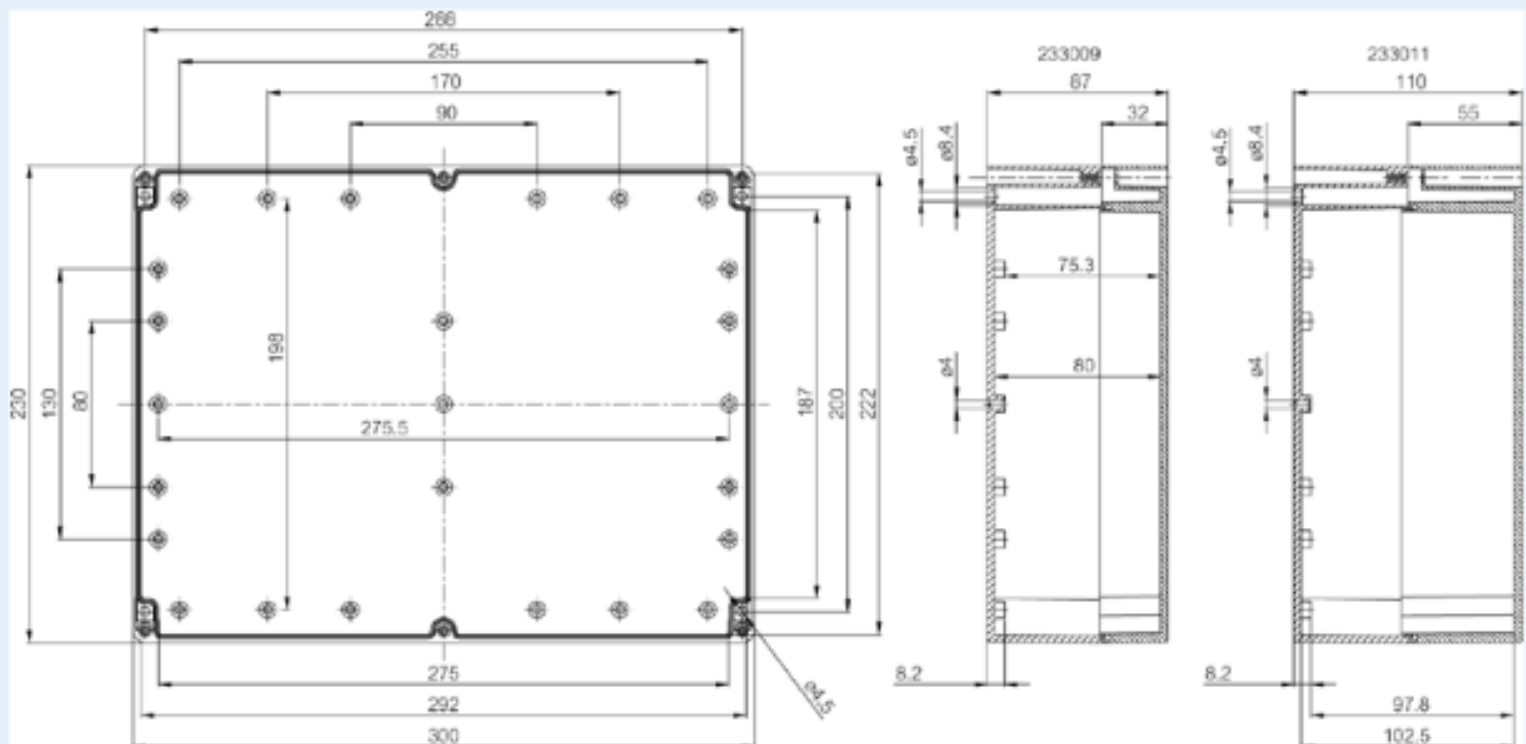

Dimensions:	Height	Width	Depth
mm:	230	300	110
inch:	9.06	11.81	4.33

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Accessories:

TF 28037	Mounting foot kit (4 pcs). for enclosures:
TRH 1216	DIN-15 Mounting rail. for enclosures: (146 x 35 x 1)
TRH 2330	DIN-15 Mounting rail. for enclosures: (285 x 35 x 1)
TRM 0816	DIN-15 Mounting rail. for enclosures: (146 x 15 x 1)
TM 2330	Back Panel. for enclosures: (221 x 274 x 1)
TH A	Gray plastic hinges (2 pcs)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

SGSFimko\_EURONORD