

# PC 2819 18 T

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** PC 2819 18 T

**Product nbr:** 5330070

UL Code: 5320070

UL Name: UL PC 2819 18 T

**Description:** Enclosure. PC



**Remarks:** Transparent cover

**Including:** Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

**EAN:** 6418074005458

**El. number:**

- Finland: 3423807
- Denmark:
- Sweden: 2539442

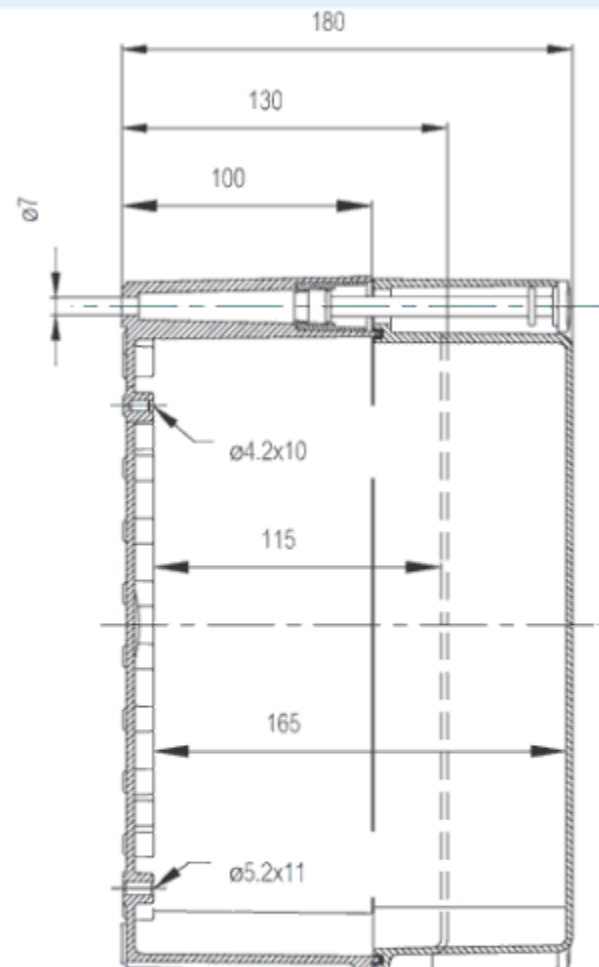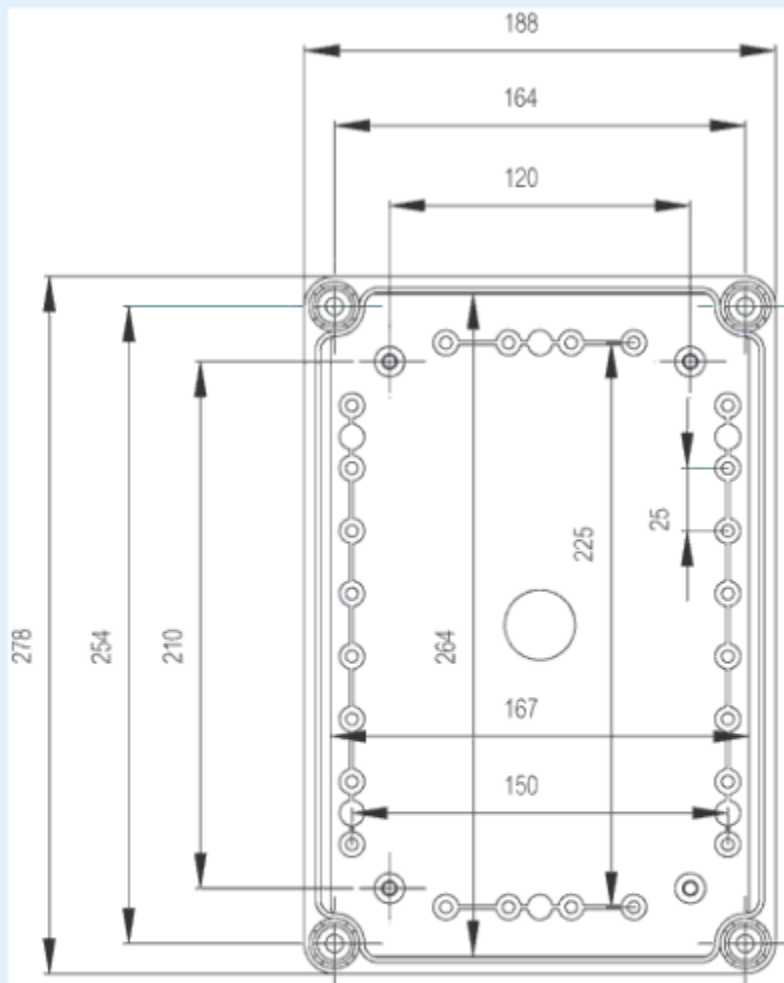

Dimensions:	Height	Width	Depth
mm:	280	190	180
inch:	11.02	7.48	7.09

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Accessories:

EKV 12	DIN-35 Mounting rail. for enclosures: (160 x 35 x 1)
EKJVT	Back Panel. for enclosures: (238 x 148 x 1)
EKV 22	DIN-35 Mounting rail. for enclosures: (235 x 35 x 1)
EKJZR	Extension frame. for enclosures: (280 x 190 x 50)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

Certificate NCS FI 30308