

# PC 2828 13 T

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** PC 2828 13 T

**Product nbr:** 5330062

**UL Code:** 5320062

**UL Name:** UL PC 2828 13 T

**Description:** Enclosure. PC



**Remarks:** Transparent cover

**Including:** Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

**EAN:** 6418074005519

**El. number:**

- Finland: 3423813
- Denmark:
- Sweden: 2539448

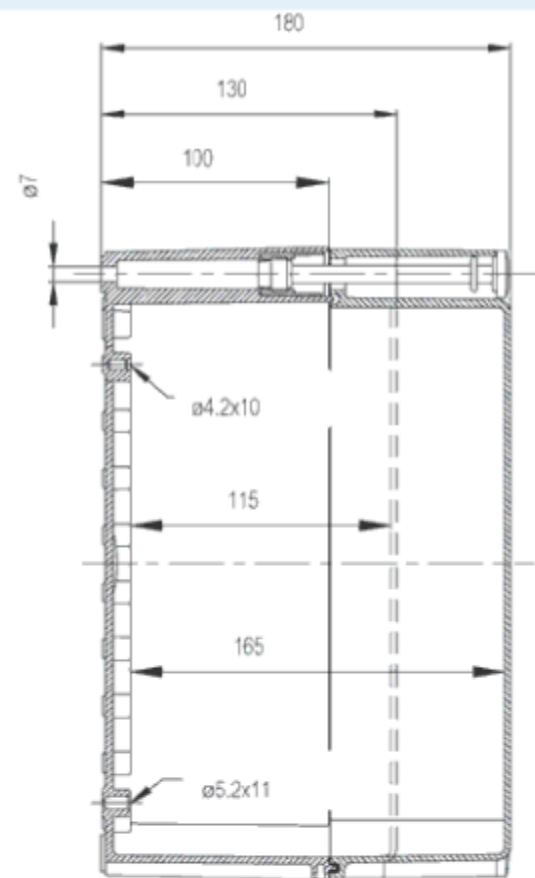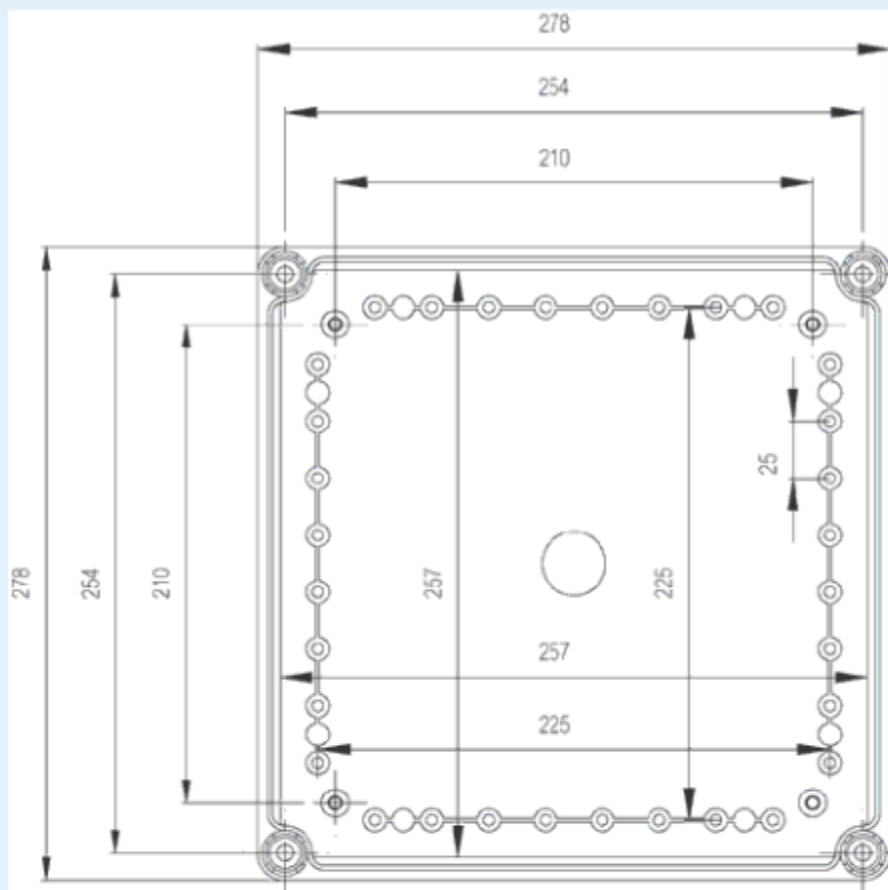

Dimensions:

Height

Width

Depth

Accessories:

mm:	280	280	130
inch:	11.02	11.02	5.12

**Materials:**

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

**Temperatures:**

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

EKOZR	Extension frame. for enclosures: (280 x 280 x 50)
EKV 22	DIN-35 Mounting rail. for enclosures: (235 x 35 x 1)
EKOVT	Back Panel. for enclosures: (238 x 238 x 1)

**Rating:**

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

**Certificates:**

Certificate NCS FI 30308