

PC 3828 18 G

FIBOX
Enclosing innovations



Sample image

Order symbol: PC 3828 18 G

Product nbr: 5330373

UL Code: 5320373

UL Name: UL PC 3828 18 G

Description: Enclosure. PC



Remarks: Opaque cover

Including: Base with screws for mounting plate. cover with PUR gasket and polyamide cover screws.

EAN: 6418074005588

EI. number:

- Finland: 3423719
- Denmark:
- Sweden: 2539424

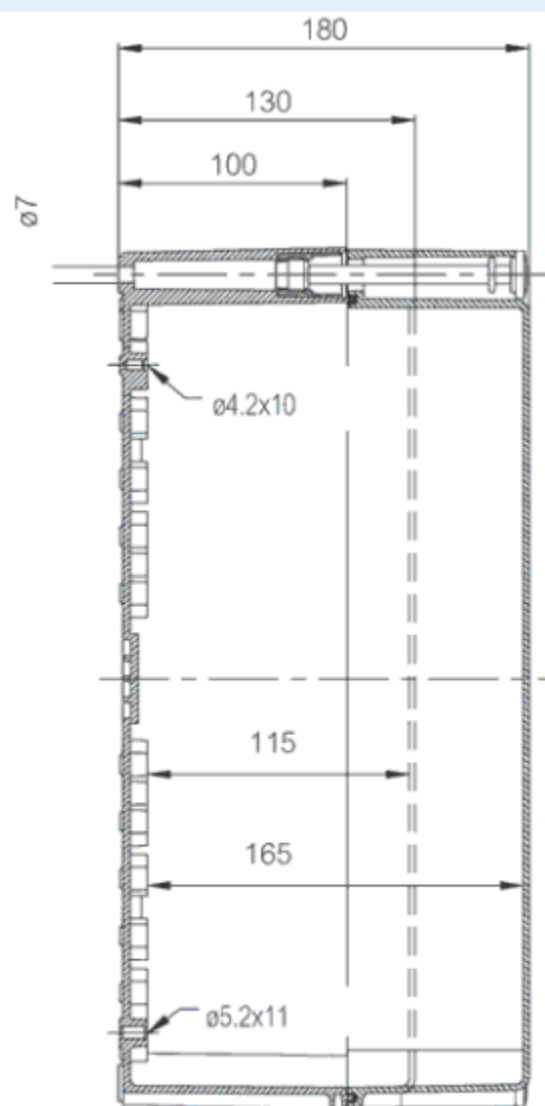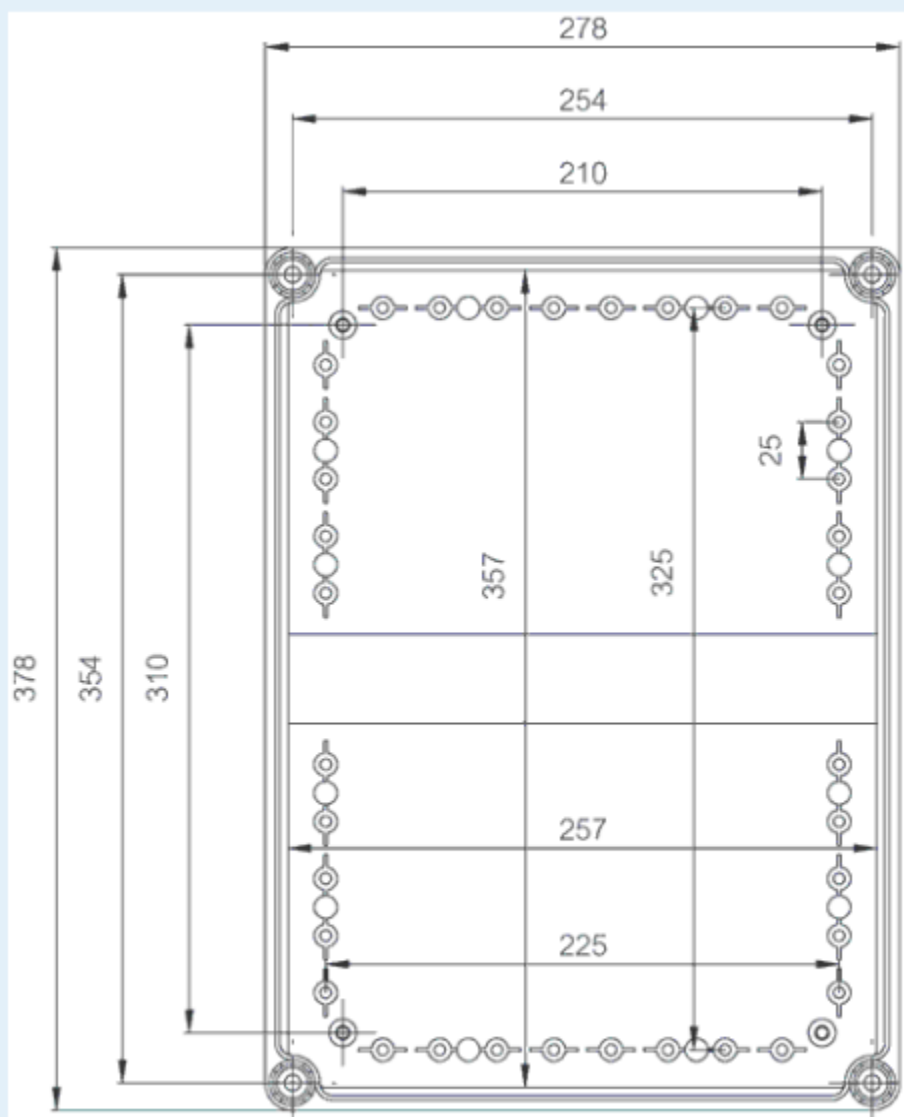

Dimensions:	Height	Width	Depth
mm:	380	280	180
inch:	14.96	11.02	7.09

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

EKV 32	DIN-35 Mounting rail. for enclosures: (335 x 35 x 1)
EKV 22	DIN-35 Mounting rail. for enclosures: (235 x 35 x 1)
EKPZR	Extension frame. for enclosures: (380 x 280 x 50)
EKPVT	Back Panel. for enclosures: (338 x 238 x 1)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate NCS FI 30308