

# PC M 95 G

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol:** PC M 95 G

**Product nbr:** 8724318

UL Code: 8714318

UL Name: UL PC M 95 G

**Description:** Enclosure. PC


**Remarks:** Opaque cover

**Including:** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and polyamide cover screws.

**EAN:** 6418074002310

**El. number:**

- Finland: 3423419
- Denmark: 8212001763
- Sweden: 2536829

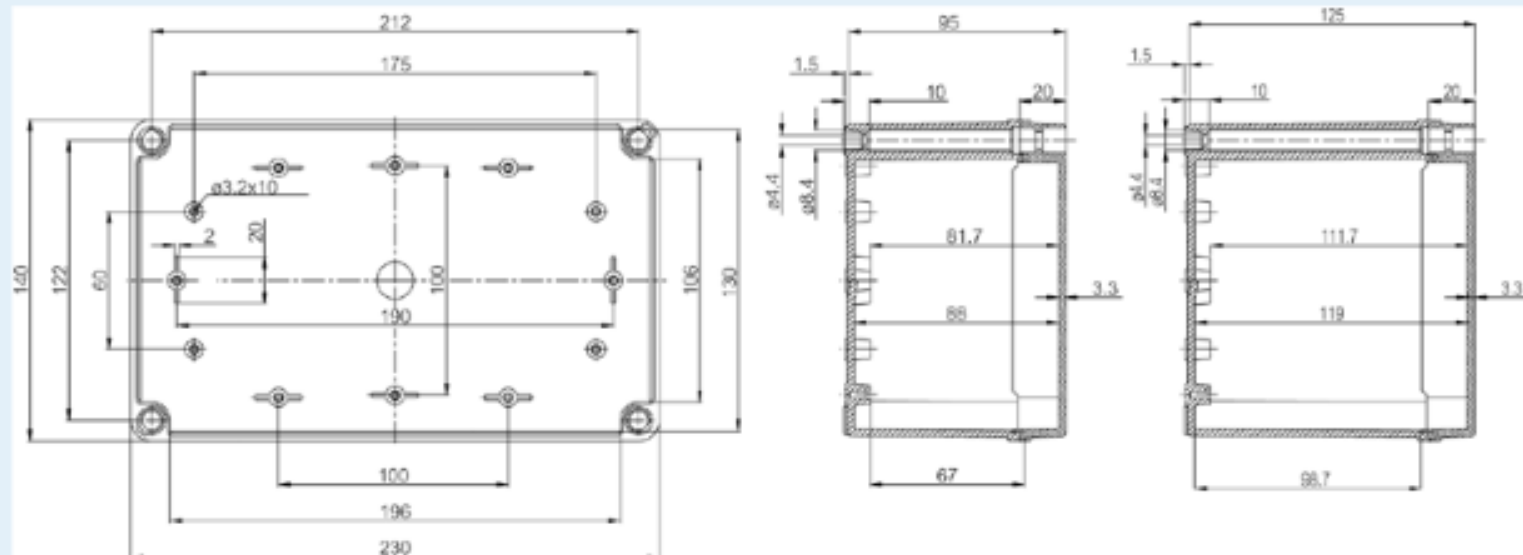

Dimensions:	Height	Width	Depth
mm:	230	140	95
inch:	9.06	5.51	3.74

#### Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

#### Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

#### Accessories:

CHM-3	DIN-35 Mounting rail. for enclosures: (110 x 35 x 1)
FM-3	DIN-35 Mounting rail. for enclosures: (35 x 200 x 1)
FP 22046	Mounting foot kit (4 pcs)
M-MP	Back Panel. for enclosures: (185 x 94 x 1)

#### Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

#### Certificates:

SGSFIMKO\_PICC\_pc