

PCT 050705

FIBOX
Enclosing innovations



Sample image

Order symbol: PCT 050705

Product nbr: 7022521

UL Code: 7032521

UL Name: UL PCT 050705

Description: Enclosure. PC


Remarks: Clear transparent cover

Including: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail. cover with PUR gasket and quick-locking cover screws.

EAN: 6418074003720

El. number:

- Finland: 3423524
- Denmark: 8212002539
- Sweden:

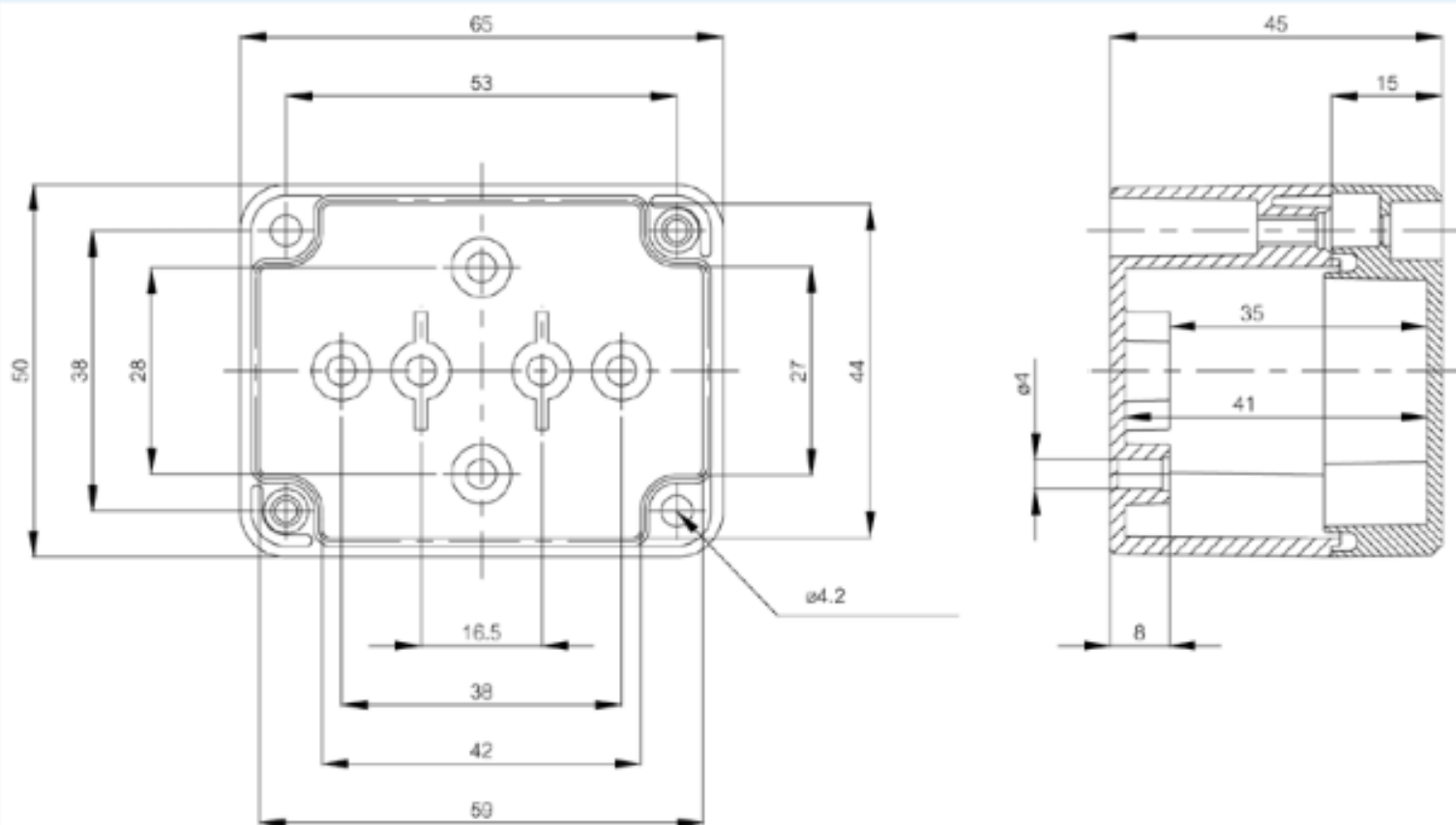

Dimensions:	Height	Width	Depth
mm:	50	65	45
inch:	1.97	2.56	1.77

Materials:

Material:	Polycarbonate
Base colour:	
Cover colour:	
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

TF 28037	Mounting foot kit (4 pcs). for enclosures:
TM 0507	Back Panel. for enclosures: (26 x 57 x 1)
TRM 0507	DIN-15 Mounting rail. for enclosures: (48 x 15 x 1)
TM 0505	Back Panel. for enclosures: (26 x 48 x 1)
TH A	Gray plastic hinges (2 pcs)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5*
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

SGSFimko_EURONORD