

Order symbol: TA131007

EAN: 6418074011480

Product nbr: 5814040

El. number:


Description: Enclosure. ABS

- Finland:
- Denmark: 8212045237
- Sweden: 5814040

Remarks: Opaque cover

Including: Base with PUR gasket and screws for mounting plate/DIN-rail. cover with polyamide cover screws and plastic hinges.

Sample image

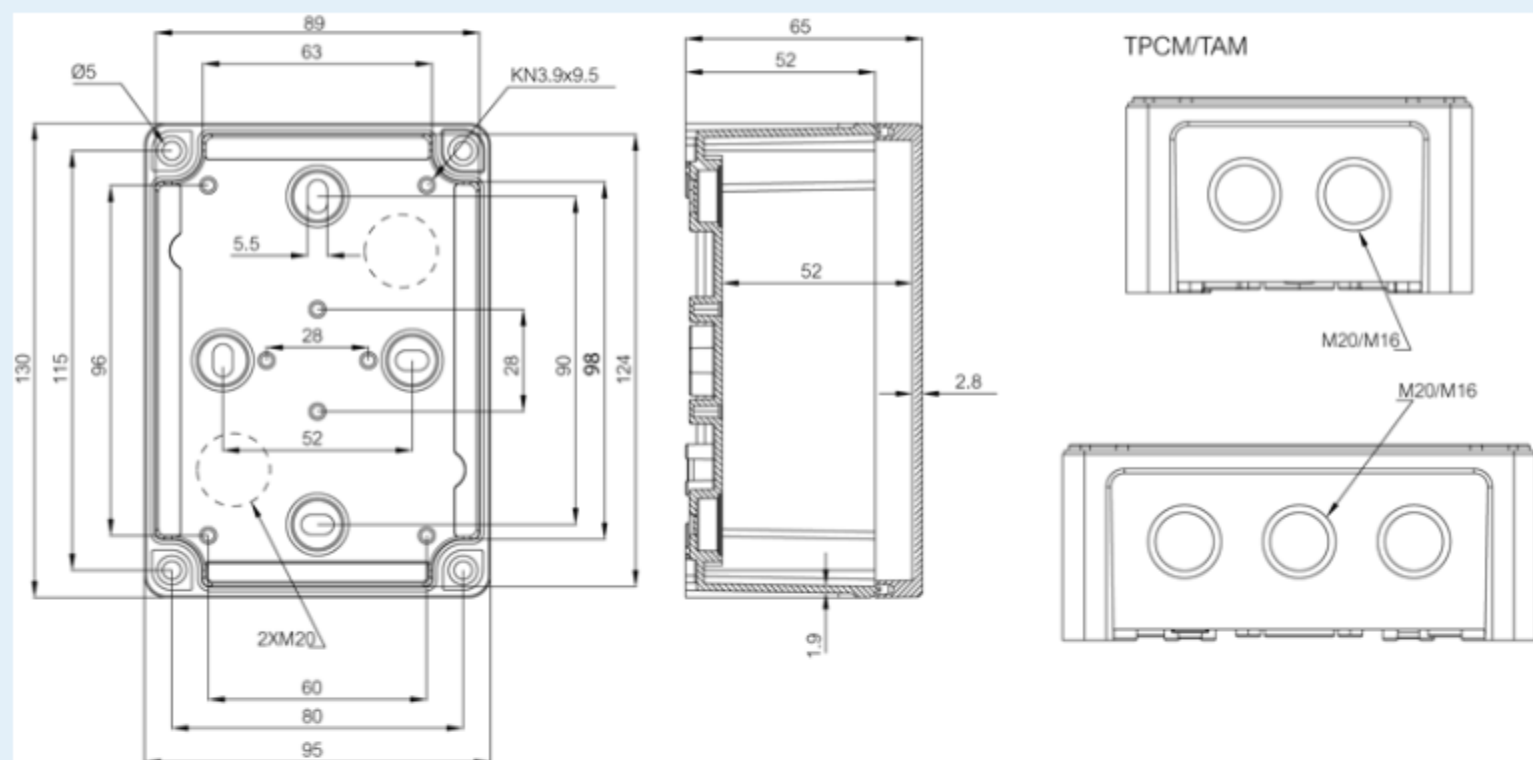

mm:	130	95	65
inch:	5.12	3.74	2.56

Materials:

Material:	ABS
Base colour:	
Cover colour:	
Gasket material:	

Temperatures:

Temperature °C (short term):	-40 ... 80
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 175
Temperature °F (continuous):	-40 ... 140

FP 10674 Mounting foot kit (2 pcs) incl. screws

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C:	650 °C
NEMA Class	

Certificates:

Certificate FI 40343
