



Sample image

Order symbol: TA241911

Product nbr: 5814002

Description: Enclosure. ABS



Remarks: Opaque cover

Including: Base with PUR gasket and screws for mounting plate/DIN-rail. cover with polyamide cover screws and plastic hinges.

EAN: 6418074060747

El. number:

- Finland: 3435686
- Denmark: 8212035043
- Sweden: 5814002

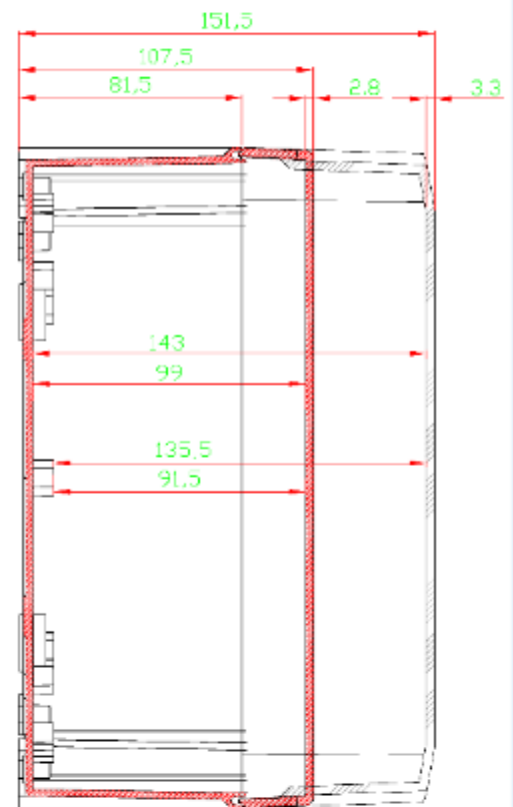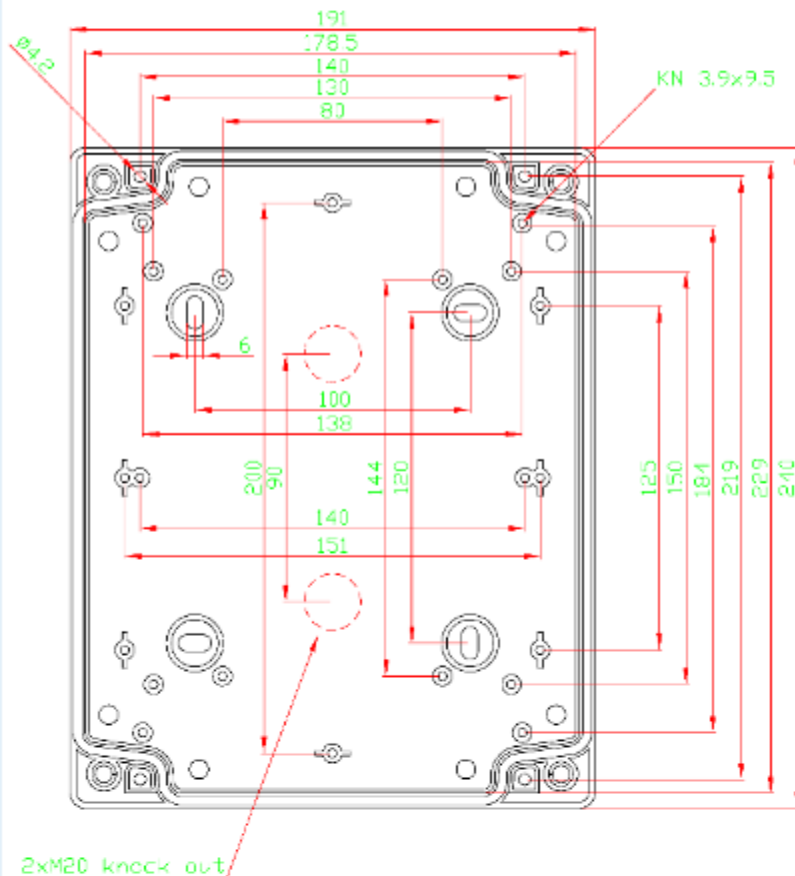

Dimensions:	Height	Width	Depth
mm:	240	191	107
inch:	9.45	7.52	4.21

Accessories:

MP 2419	Mounting plate. for enclosures:
EKV 12	DIN-35 Mounting rail. for enclosures: (160 x 35 x 1)
DR 210	DIN-35 Mounting rail. for enclosures: (210 x 35 x 1)

Materials:

Material:	ABS
Base colour:	
Cover colour:	
Gasket material:	

Temperatures:

Temperature °C (short term):	-40 ... 80
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 175
Temperature °F (continuous):	-40 ... 140

(2 10 x 35 x 1)

FP 10674 Mounting foot kit (2 pcs) incl. screws

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C:	650 °C
NEMA Class	

Certificates:

Certificate FI 40343