


# TM 1625

---

**FIBOX**  
Enclosing innovations

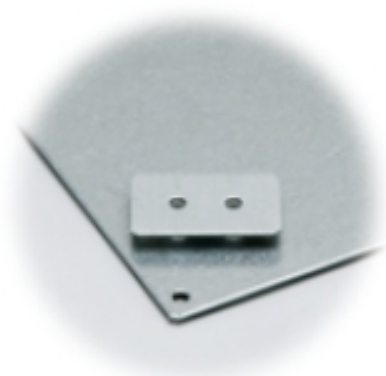

Sample image

**Order symbol:** TM 1625

**Product nbr:** 9512018

**Description:** Back Panel, for enclosures:

**Remarks:** 250x160x90-250x160x150

**Including:**

**EAN:** 6418074034076

**El. number:**

- Finland: 3423928
- Denmark: 8212004029
- Sweden: 2536165

| Dimensions: | Height | Width | Depth |
|-------------|--------|-------|-------|
| mm:         | 151    | 214   | 1     |
| inch:       | 5.94   | 8.43  | 0.04  |

#### Materials:

Material:

Base colour:

Cover colour:

Gasket material:

#### Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

#### Rating:

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation: Not insulated

Halogen free (DIN/VDE 0472, Part 815): 0

UV resistance: -

Flammability Rating:

Glow Wire Test (IEC 695-2-1) °C: C

NEMA Class

#### Certificates: