

# TPC 241911



Sample image

**Order symbol:** TPC 241911

**Product nbr:** 5824002

UL Code: 5854002

UL Name: UL TPC 241911

**Description:** Enclosure. PC



**Remarks:** Opaque cover

**EAN:** 6418074078780

**Including:**

**El. number:**

- Finland:
- Denmark:
- Sweden:

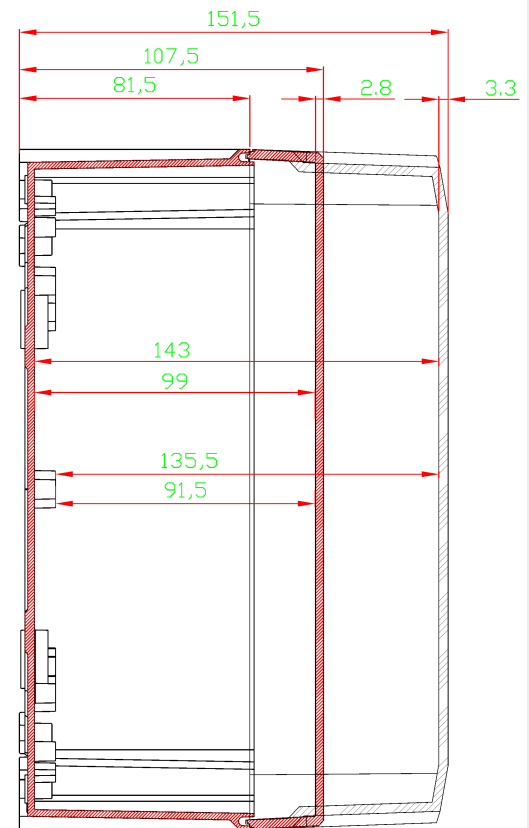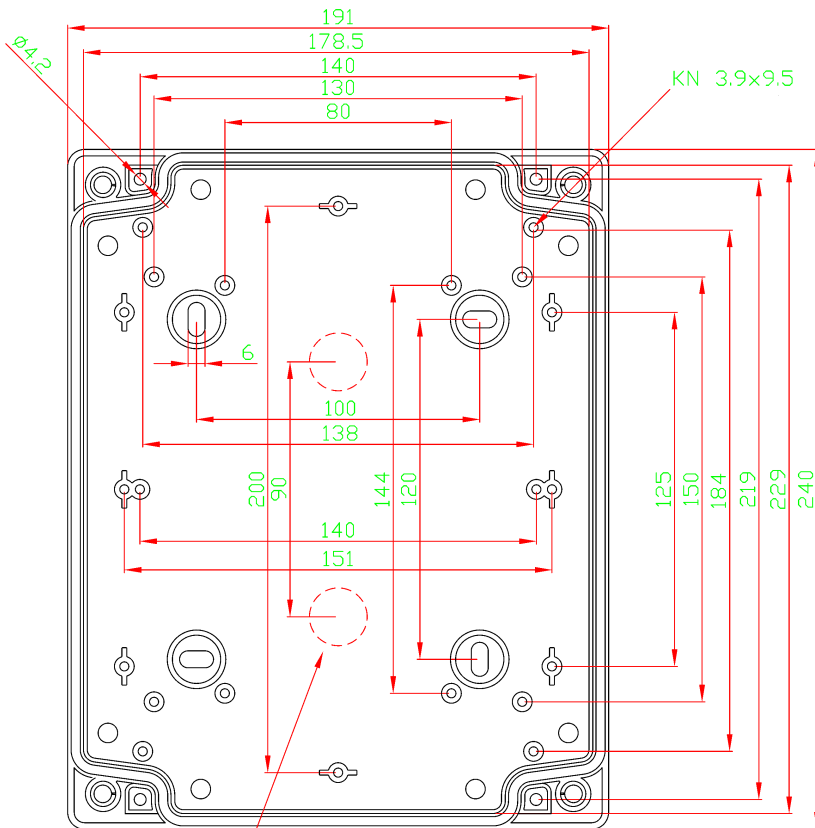

**Dimensions:**

**Height**

**Width**

**Depth**

**Accessories:**

mm:	240	191	107
inch:	9.45	7.52	4.21

**Materials:**

Material: Polycarbonate  
 Base colour:  
 Cover colour:  
 Gasket material:

**Temperatures:**

Temperature °C (short term):: -40 ... 120  
 Temperature °C (continuous):  
 Temperature °F (short term): -40 ... 250  
 Temperature °F (continuous): -40 ... 175

MP 2419	Mounting plate. for enclosures: (210 x 160 x 0)
EKV 12	DIN-35 Mounting rail. for enclosures: (160 x 35 x 1)
DR 210	DIN-35 Mounting rail. for enclosures: (210 x 35 x 1)
FP 10674	Mounting foot kit (2 pcs) incl. screws

**Rating:**

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

**Certificates:**

Certificate FI 40343