

# TPC 292411



Sample image

**Order symbol:** TPC 292411

**Product nbr:** 5824003

**Description:** Enclosure. PC



**Remarks:** Opaque cover

**EAN:** 6418074078797

**Including:**

**El. number:**

- Finland:
- Denmark:
- Sweden:

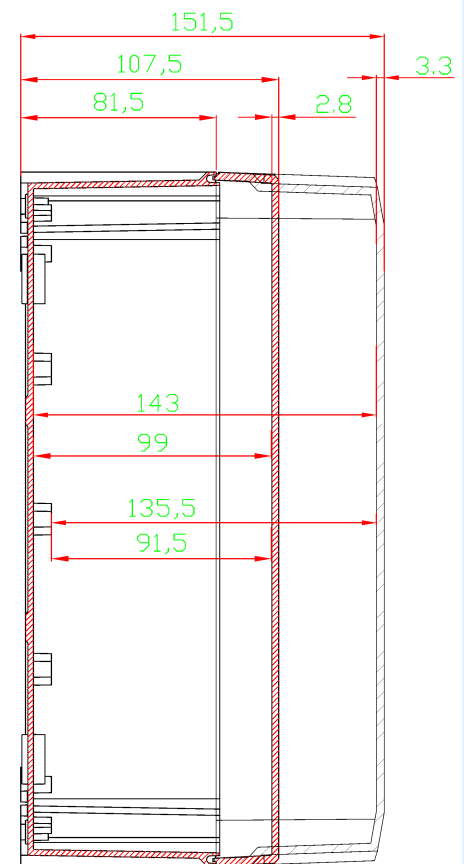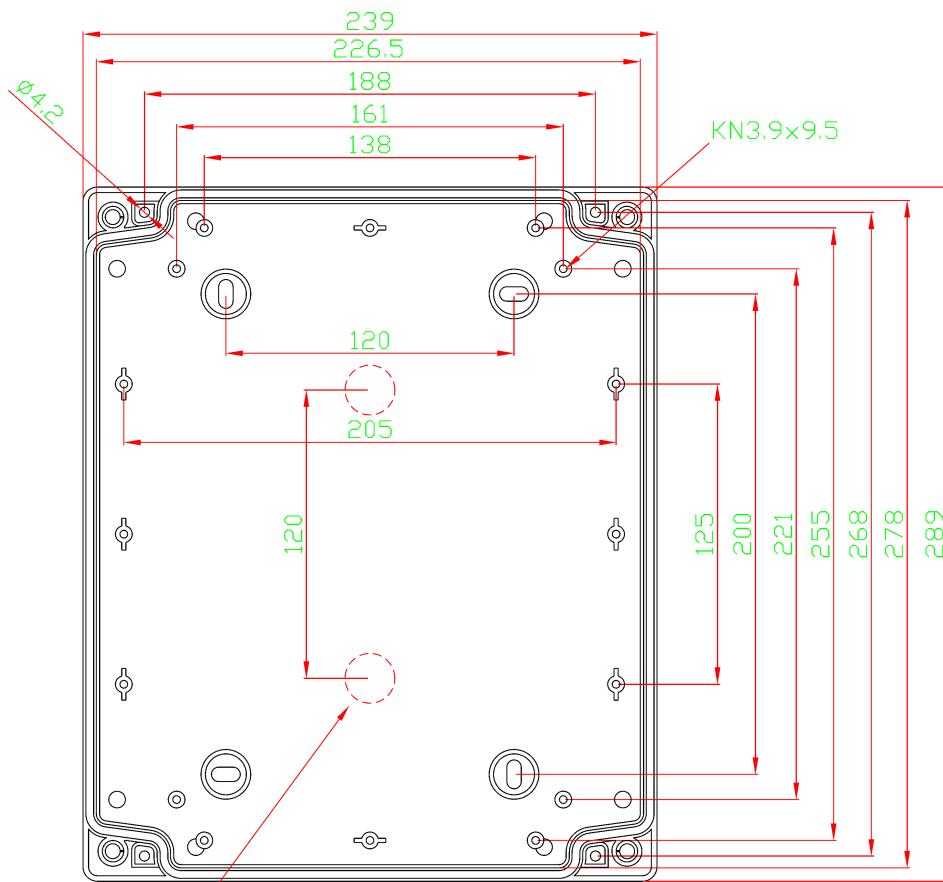

**Dimensions:**

**Height**

**Width**

**Depth**

**Accessories:**

mm:	289	239	107
inch:	11.38	9.41	4.21

**Materials:**

Material: Polycarbonate  
 Base colour:  
 Cover colour:  
 Gasket material:

**Temperatures:**

Temperature °C (short term):: -40 ... 120  
 Temperature °C (continuous):  
 Temperature °F (short term): -40 ... 250  
 Temperature °F (continuous): -40 ... 175

MP 2924	Mounting plate. for enclosures: (265 x 215 x 0)
DR 215	DIN-35 Mounting rail. for enclosures: (215 x 35 x 1)
DR 265	DIN-35 Mounting rail. for enclosures: (265 x 35 x 1)
FP 10674	Mounting foot kit (2 pcs) incl. screws

**Rating:**

Ingress protection (EN 60529): IP65;  
 Impact Resistance (EN 62262): IK07; IK08;  
 Electrical insulation: Totally insulated  
 Halogen free (DIN/VDE 0472, Part 815): 1  
 UV resistance: -  
 Flammability Rating: UL 746C 5"  
 Glow Wire Test (IEC 695-2-1) °C: 960 °C  
 NEMA Class

**Certificates:**

Certificate FI 40343