

TPC 342912



Sample image

Order symbol: TPC 342912

Product nbr: 5824004

Description: Enclosure. PC



Remarks: Opaque cover

EAN: 6418074086877

Including:

El. number:

- Finland:
- Denmark:
- Sweden:

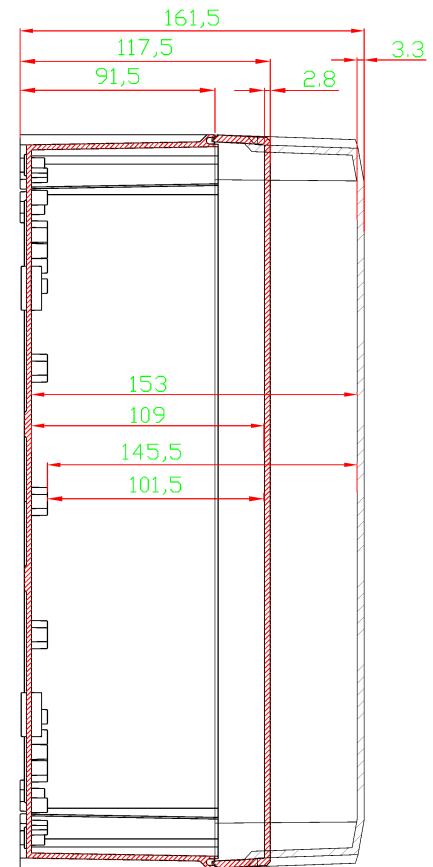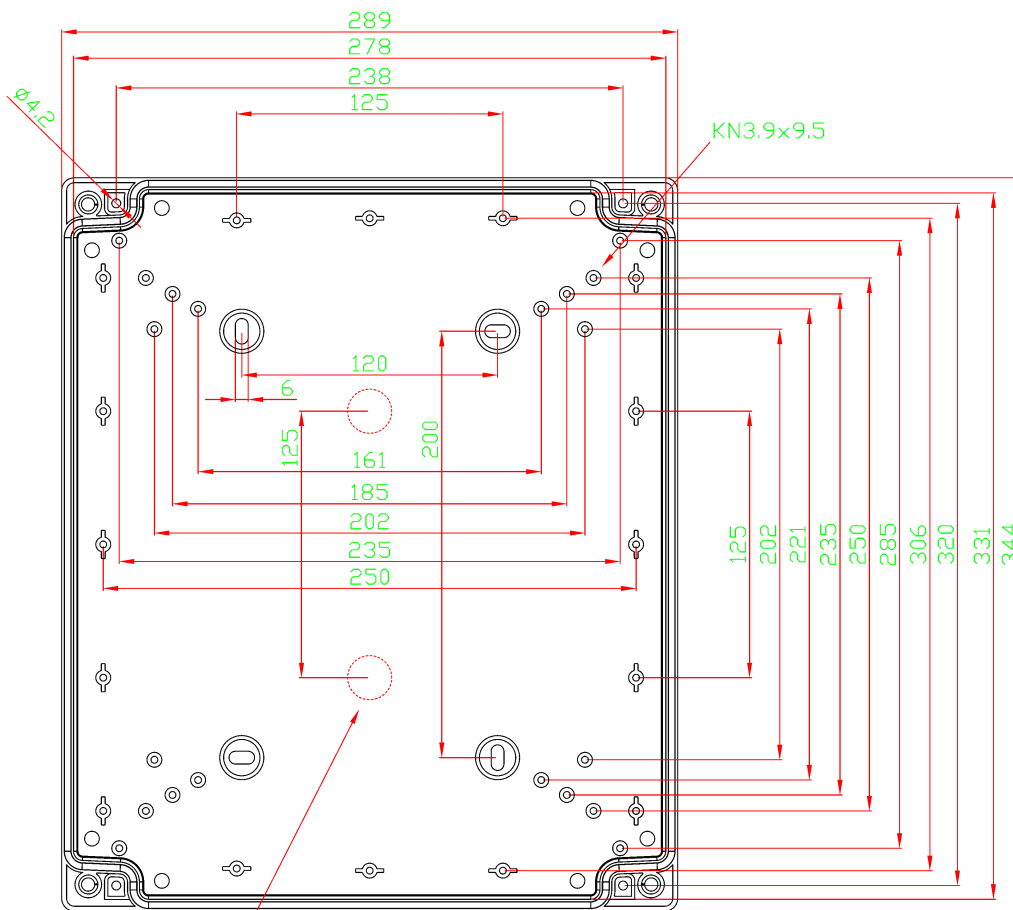

2xM20 knock out

Dimensions:

Height

Width

Depth

Accessories:

mm:	344	289	117
inch:	13.54	11.38	4.61

Materials:

Material:	Polycarbonate
Base colour:	
Cover colour:	
Gasket material:	

Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

MP 3429	Mounting plate. for enclosures: (315 x 265 x 0)
ARH 2328	DIN-35 Mounting rail. for enclosures: (260 x 35 x 1)
FP 10674	Mounting foot kit (2 pcs) incl. screws
DR 316	DIN-35 Mounting rail. for enclosures: (316 x 35 x 1)

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07; IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	-
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate FI 40343