

EKJ 30-T



Sample image

Order symbol : EKJ 30-T

Product nr : 3720146



Description : Cover, PC

Remarks : Transparent

EAN : 6418074000224

El. number :

- Finland : 3420155
- Denmark : 8212007042
- Sweden : 2537854

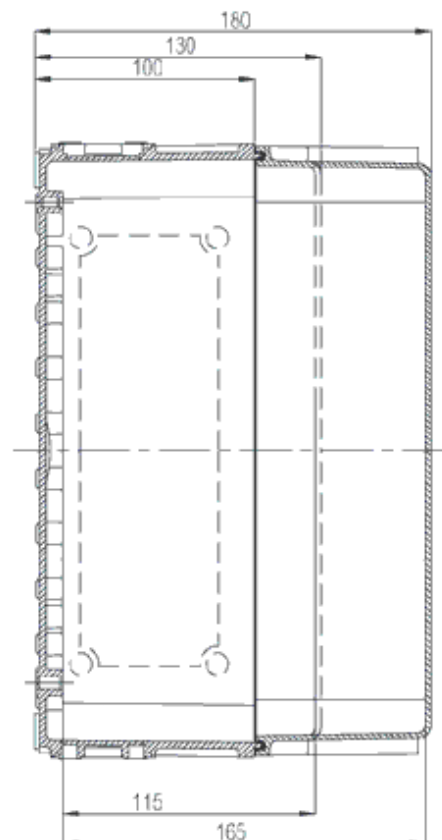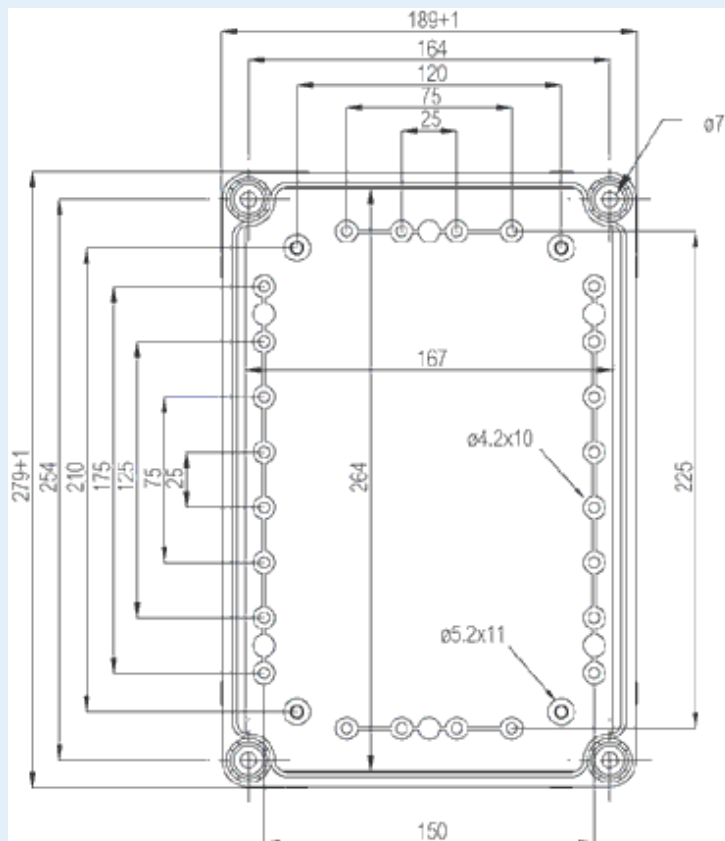

Dimensions :	Height	Width	Depth
mm :	280	190	30
inch :	11.02	7.48	1.18

Materials :

Temperatures :	
Temperature °F (continuous) :	-40 ... 175

Accessories :	
EKV 12	DIN-35 Mounting rail, for enclosures: (160 x 35 x 1)
EKJVT	Mounting plate, for enclosures: (238 x 148 x 1)
EKV 22	DIN-35 Mounting rail, for enclosures: (235 x 35 x 1)
EKJZR	Extension frame, for enclosures: (280 x 190 x 50)
MPI EKJ 2819	Multiperforated plastic mounting plate (259 x 164 x 4)

Ratings :	
electrical_insulation :	Totally insulated
UV resistance :	UL 746C

Certificates :
SGSFIMKO_EK