

# ARCA 302015W

**FIBOX**  
Enclosing innovations



Sample image

**Order symbol :** ARCA 302015W

**Product nr :** 8120122

UL Code : UL508A

**Description :** Cabinet, PC


**Remarks :** Grey cover with window, 1-point locking, hinges on the long side

**EAN :** 6418074079916

**El. number :**

- Finland : 3423190
- Denmark : 8212091786
- Sweden : 2500138

**Including :** Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

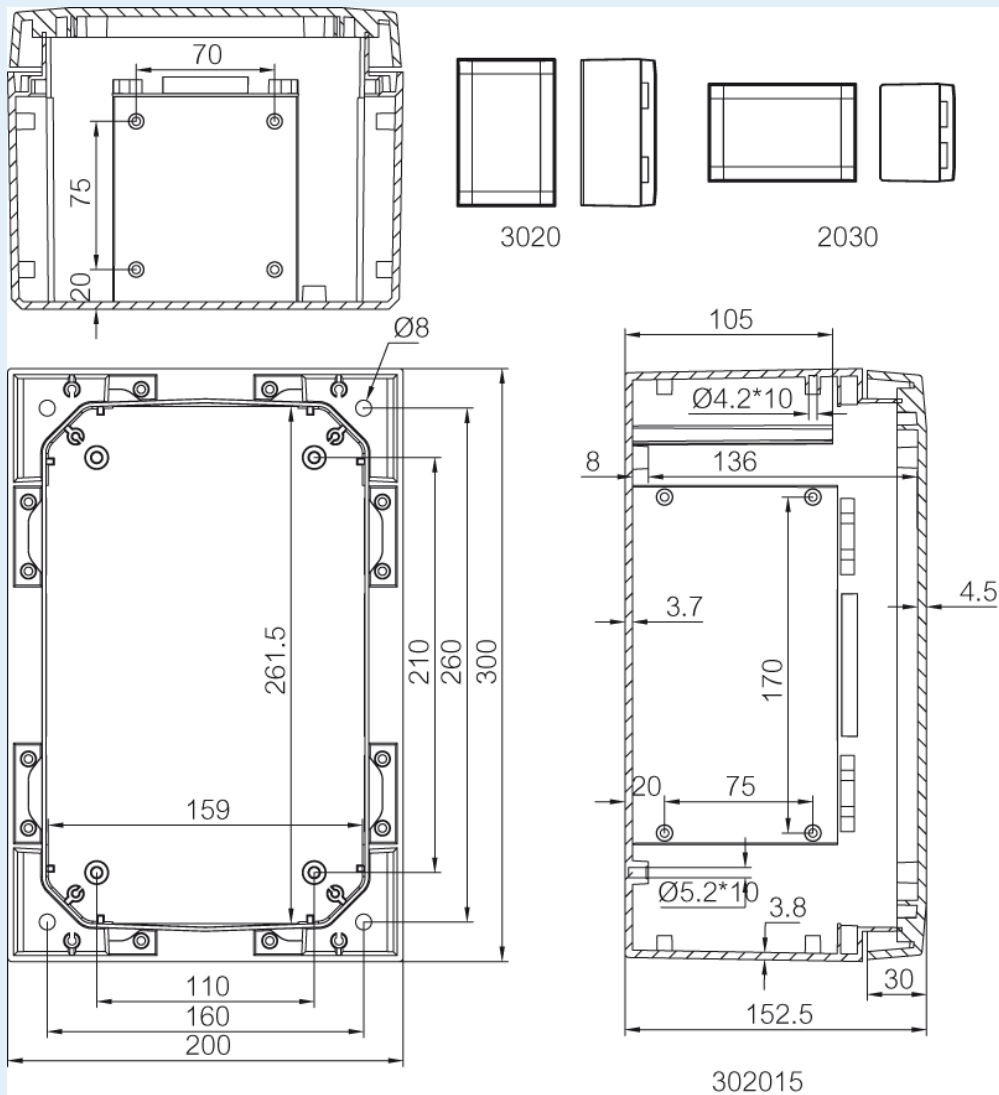

302015

#### Dimensions :

|        | Height | Width | Depth |
|--------|--------|-------|-------|
| mm :   | 300    | 200   | 150   |
| inch : | 11.81  | 7.87  | 5.91  |

#### Materials :

|                   |                   |
|-------------------|-------------------|
| Material :        | Polycarbonate     |
| Base colour :     | RAL_7035          |
| Cover colour :    | Clear transparent |
| Gasket material : | Polyurethane      |

#### Temperatures :

|                               |             |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (continuous) : | -40 ... 175 |

#### Accessories :

|                 |                                                                        |
|-----------------|------------------------------------------------------------------------|
| MPP ARCA 3020   | Mounting plate perforated (250x150x2 mm - 26x11 mm)<br>(250 x 150 x 2) |
| DRS ARCA 302015 | DIN rail frame set<br>(285 x 185 x 35)                                 |
| MPMP ARCA 3020  | Mounting plate multiperforated (250x150x2 mm - ø3.6 mm)                |
| PMK ARCA 20     | PoleMounting kit, for pole ø100-300mm<br>(385 x 285 x 35)              |
| RCS ARCA 3020   | Rain canopy set for size 3020                                          |
| MPS ARCA 3020   | Mounting plate (250x150x2 mm)<br>(250 x 150 x 2)                       |
| IDS ARCA 3020   | Inner door set<br>(285 x 185 x 35)                                     |
| MPX ARCA 3020   | Mounting plate (250x150 mm)<br>(250 x 150 x 20)                        |

#### Ratings :

|                                |                   |
|--------------------------------|-------------------|
| Ingress protection (EN 60529): | IP65;             |
| Impact Resistance (EN 62262):  | IK08;             |
| electrical_insulation :        | Totally insulated |

|                                         |           |
|-----------------------------------------|-----------|
| Halogen free (DIN/VDE 0472, Part 815) : | Yes       |
| UV resistance :                         | UL 746C   |
| Flammability Rating :                   | UL 94 5VA |
| Glow Wire Test (IEC 695-2-1) °C :       | 960C      |

**Certificates :**

Certificate FI 40467