


Pre-insulated Crimp Terminal Assortment, 520pcs Flat Blade/ Blade receptacle / Ring Lugs / Fork Lugs

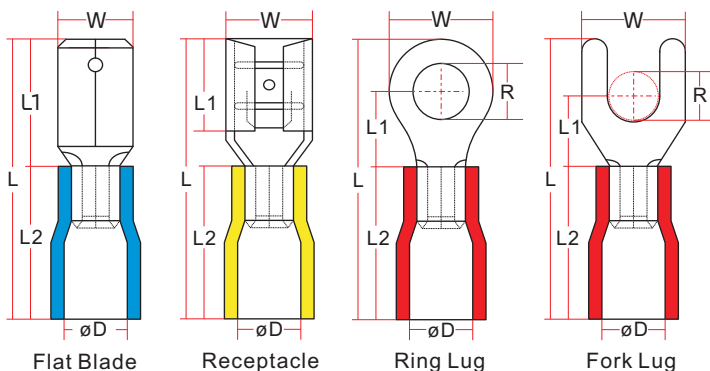

Terminal material : Flat Blade - Brass
: Receptacle - Brass
: Ring lugs - Copper
: Fork Lugs - Copper

Terminal plating : Tin

Terminal thickness : 0.4 mm

Rated voltage : 300V

Rated current : Red - 10A max.
: Blue - 15A max.
: Yellow - 19A max.

Rated temperature : 75°C max.

Wire Guide	Cross Section	Insulator color	Terminal	Tab size / Stud size	Dimension (mm)						Quantity
					L	L1	L2	ØD	W	ØR	
20-17 AWG	0.5-1.0 mm²	Red	Flat Plug	6.3 x 0.8	21.5±1.0	11.0±0.5	10.5±0.5	3.8±0.3	6.3±0.3		50 Pcs
			Receptacle	6.3 x 0.8	21.0±1.0	7.36±0.5	10.5±0.5	3.8±0.3	7.3±0.3		50 Pcs
			Ring Lugs	M4	20.0±1.0	6.3±0.5	10.5±0.5	4.3±0.3	6.6±0.3	4.3±0.1	50 Pcs
			Fork Lugs	M4	21.6±1.0	7.5±0.5	10.5±0.5	4.3±0.3	6.5±0.3	4.3±0.1	50 Pcs
16-14 AWG	1.5-2.5 mm²	Blue	Flat Plug	6.3 x 0.8	21.5±1.0	11.0±0.5	10.5±0.5	4.3±0.3	6.3±0.3		50 Pcs
			Receptacle	6.3 x 0.8	20.9±1.0	7.5±0.5	10.5±0.5	4.5±0.3	7.5±0.3		50 Pcs
			Ring Lugs	M5	22.4±1.0	7.8±0.5	10.5±0.5	4.7±0.3	8.5±0.3	5.2±0.2	50 Pcs
			Fork Lugs	M5	21.5±1.0	6.5±0.5	10.5±0.5	4.7±0.3	8.1±0.3	5.2±0.2	50 Pcs
12-10 AWG	4.0-6.0 mm²	Yellow	Flat Plug	6.3 x 0.8	24.5±1.0	11.0±0.5	13.5±0.5	5.7±0.3	6.3±0.3		30 Pcs
			Receptacle	6.3 x 0.8	23.7±1.0	7.4±0.5	13.5±0.5	5.7±0.3	7.5±0.3		30 Pcs
			Ring Lugs	M6	29.8±1.0	10.5±0.5	13.5±0.5	6.4±0.3	12.1±0.3	6.3±0.2	30 Pcs
			Fork Lugs	M6	25.7±1.0	7.5±0.5	13.5±0.5	6.4±0.3	9.0±0.3	6.3±0.2	30 Pcs