


Pre-Insulated Crimp Ring Terminal, 505pcs 0.5 - 6.0mm² Wire size, M3 - M8 Stud size

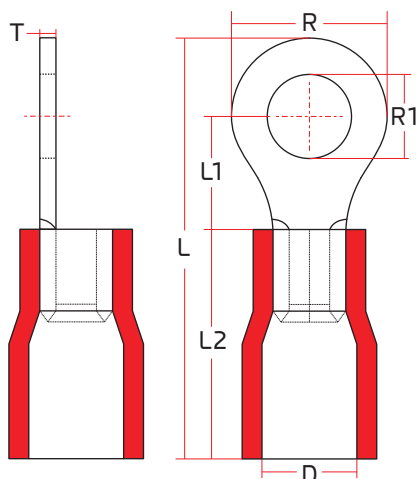

Specification

Termination method	: Crimp
Insulation type	: pre-insulation
Insulation material	: PVC
Insulator color	: Red/Blue/Yellow
Terminal material	: Copper
Terminal plating	: Tin
Rated voltage	: 300V max.
Rated current	: Red - 9A : Blue-10A : Yellow - 15A
Rated temperature	: -10° ~ 75°C

Wire Guide	Cross Section	Color	Dimension (mm)							Stud size	Quantity
			L	L1	L2	øD	T	R	øR1		
20-17 AWG	0.5-1.0 mm ²	Red	18.0 ±1.0	5.0 ±0.5	10.5 ±0.5	4.3 ±0.3	0.7 ±0.05	5.7 ±0.2	3.15 ±0.2	M3	50 Pcs
			20.0 ±1.0	6.3 ±0.5	10.5 ±0.5	4.3 ±0.3	0.6 ±0.05	6.6 ±0.2	4.2 ±0.2	M4	50 Pcs
			21.2 ±1.0	7.5 ±0.5	10.5 ±0.5	4.3 ±0.3	0.7 ±0.05	8.1 ±0.2	5.2 ±0.2	M5	50 Pcs
16-14 AWG	1.5-2.5 mm ²	Blue	17.9 ±1.0	4.3 ±0.5	10.5 ±0.5	4.7 ±0.3	0.7 ±0.05	6.6 ±0.2	3.15 ±0.2	M3	75 Pcs
			20.2 ±1.0	7.0 ±0.5	10.5 ±0.5	4.7 ±0.3	0.7 ±0.05	6.6 ±0.2	4.2 ±0.2	M4	60 Pcs
			22.4 ±1.0	7.8 ±0.5	10.5 ±0.5	4.7 ±0.3	0.6 ±0.05	8.5 ±0.2	5.2 ±0.2	M5	50 Pcs
			22.3 ±1.0	7.6 ±0.5	10.5 ±0.5	4.7 ±0.3	0.65 ±0.05	9.6 ±0.2	6.4 ±0.2	M6	40 Pcs
			27.5 ±1.0	11.3 ±0.5	10.5 ±0.5	4.7 ±0.3	0.7 ±0.05	12.1 ±0.2	8.3 ±0.2	M8	25 Pcs
12-10 AWG	4.0-6.0 mm ²	Yellow	22.8 ±1.0	6.0 ±0.5	13.5 ±0.5	6.4 ±0.3	0.85 ±0.05	7.2 ±0.2	4.3 ±0.2	M4	25 Pcs
			26.2 ±1.0	8.5 ±0.5	13.5 ±0.5	6.4 ±0.3	0.85 ±0.05	9.5 ±0.2	5.2 ±0.2	M5	30 Pcs
			29.8 ±1.0	10.5 ±0.5	13.5 ±0.5	6.4 ±0.3	0.85 ±0.05	12.1 ±0.2	6.3 ±0.2	M6	30 Pcs
			34.3 ±1.0	14.0 ±0.5	13.5 ±0.5	6.4 ±0.3	0.8 ±0.05	15.1 ±0.2	8.3 ±0.2	M8	20 Pcs