


Data Sheet

320pcs Male/Female pin head connectors
set/wire to wire/wire to board

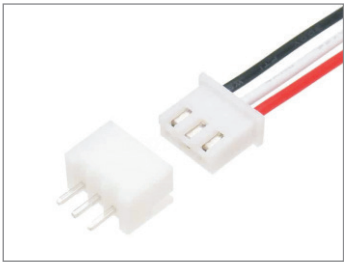

Specification

Material:
Terminal:Phosphor bronze,Tin plated
Housing:PA66,UL94V-2
Wire range:AWG#30~22
Voltage rating:250V/AC max.
Current rating:3A max.
Contact resistance:≤0.02Ω
Insulation resistance:≥1000MΩ
Withstand voltage:1kVAC/30sec.
Working Temperature:-20℃~85℃

				2.5 Pin Terminal	80pcs
				2.5 Receptacle Terminal	80pcs
				2.0 Pin Terminal	20pcs
				2.0 Receptacle Terminal	20pcs
				2.0 Wire to Board Wafer Connector, 2 Pole	15pcs
				2.54 Wire to Board Wafer Connector, 2 Pole	15pcs
				2.54 Wire to Board Wafer Connector, 3 Pole	15pcs
				2.54 Wire to Board Wafer Connector, 4 Pole	15pcs
				2.0 Receptacle Terminal Housing, 2 Pole	15pcs
				2.54 Receptacle Terminal Housing, 2 Pole	15pcs
				2.54 Receptacle Terminal Housing, 3 Pole	15pcs
				2.54 Receptacle Terminal Housing, 4 Pole	15pcs