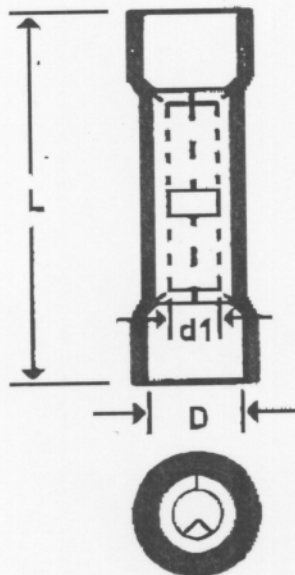


Order code	Manufacturer code	Description
33-1044	n/a	RED BUTT CONNECTOR PK100 (RC)

	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

DESCRIPTION Data Sheets For Standard Industrial Light Duty Terminals				QUALITY SYSTEM No: DAV1850
DRAWN BY: M.TAMAN	SIGNED: <i>Alan</i>	ISSUE DATE: 30-01-2001	DRAWING SCALE SIZE: N/A	SHEET 3 of 12


INSULATED BUTT / SPLICE TERMINALS

Working Voltage	600 V.Max AC or DC
Working Temperature	-40 To +85 Deg C
Basic Tolerance	±0.5 mm
Insulation	Vinyl

For Further Technical Specification
Refer To DAV 1069 Sheets 1 To 4

Butt Terminal To Centre Of Insulation
Housing + or - 1mm

Davico Part No.	Stud Size	D (mm)	E (mm)	F (mm)	L (mm)	T (mm)	W (mm)	d1 (mm)	d2 (mm)
ERB	N/A	4.0	N/A	N/A	24.6	N/A	N/A	1.7	N/A
EBB	N/A	4.5	N/A	N/A	24.6	N/A	N/A	2.3	N/A
EYB	N/A	6.3	N/A	N/A	26.5	N/A	N/A	3.4	N/A

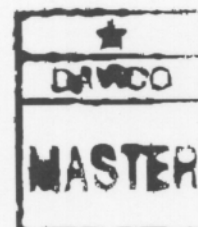**UNCONTROLLED****DAVICO**

Keeping electricity firmly in its place.

Davico Industrial Limited, Charles Street, West Bromwich, West Midlands, B70 6AZ, U.K.
Tel: (0121) 520-7101/3040. Fax: (0121) 520-7775 (SALES) / (0121) 520-0035 (ENQUIRES)
E-Mail sales: sales@davico.co.uk Enquiries: enq@davico.co.uk
World Wide Web: <http://www.davico.co.uk>

REV 1	DATE		SIG.
REV 2	DATE		SIG.
REV 3	DATE		SIG.

31/07