

## Stainless Steel Pan Head Pozidriv Screws

A range of Pan Head Pozidriv, ISO metric, coarse threaded stainless steel screws. Resistant to corrosion, chemicals and heat. Applications include electronic, domestic, chemical and construction use, as well as in food and medical environments.

### Meets the following - Standards / Specifications


DIN 7985A 4.8

ISO 7045

BN 384

### Technical Specification

Material:	Stainless Steel
Resistance Class:	4.8
Stress Resistance:	min. 420 N/mm <sup>2</sup>
Tensile Strength:	min. 340 N/mm <sup>2</sup>
Rupture Length:	min. 14%

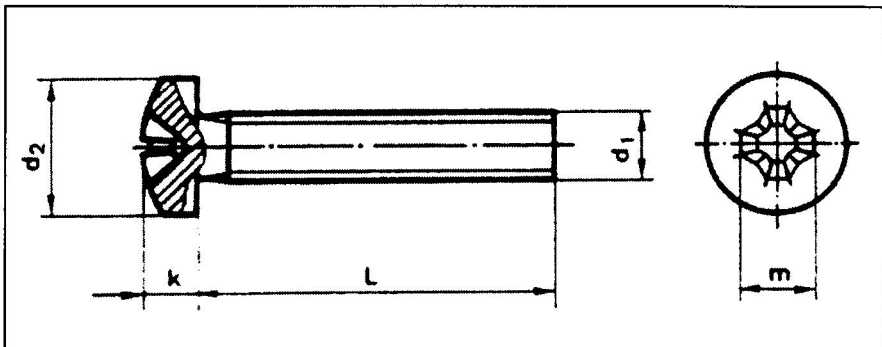

Thread Size (d1)	Screw Length (L)	Screw Dimensions (mm)		
		d <sub>2</sub>	k	m
M2.5	6 mm	5	2	2.7
M2.5	12 mm	5	2	2.7
M3	6 mm	6	2.4	3.1
M3	12 mm	6	2.4	3.1
M3	20 mm	6	2.4	3.1
M3	25 mm	6	2.4	3.1
M4	6 mm	8	3.1	4.6
M4	12 mm	8	3.1	4.6
M4	20 mm	8	3.1	4.6
M4	25 mm	8	3.1	4.6