

Pan Head Slotted Drive Machine Screws - Packs of 100



DESCRIPTION

Pan Head Slotted Machine Screws with bright zinc-plated, passivated finish.

DISTINCTIVE FEATURES

- Slotted Drive
- Zinc & Clear Cr3 Finish
- Steel Grade 4.8
- Dome head style
- M2.5, M3, M4 and M5 options
- Supplied in packs of 100


APPLICATIONS

Suitable for general use. Typical applications include use in electronic and domestic equipment, general repair and maintenance, circuit board mounting, prototyping, etc.

**Pan
Head**

**Grade
4.8
Steel**

**Zinc
& Clear
Cr3**

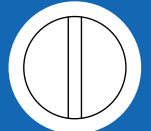



GENERAL SPECIFICATION

Series	Machine Screw
Type	Slotted Drive



MATERIALS

Material	Grade 4.8 Steel
Finish	Zinc & Clear Cr3



CERTIFICATION AND STANDARDS

Material Specification	DIN 85 ~ISO 1580
------------------------	------------------





OPTIONS (MOQ may apply)

Lengths	Various
Thread Sizes	M1.6 to M12
Thread Type	Coarse and Fine
Material	Steel
Head Styles	e.g. Button, Countersunk, Cheese



DIMENSIONS/DRAWINGS

Units	mm - unless stated otherwise
-------	------------------------------

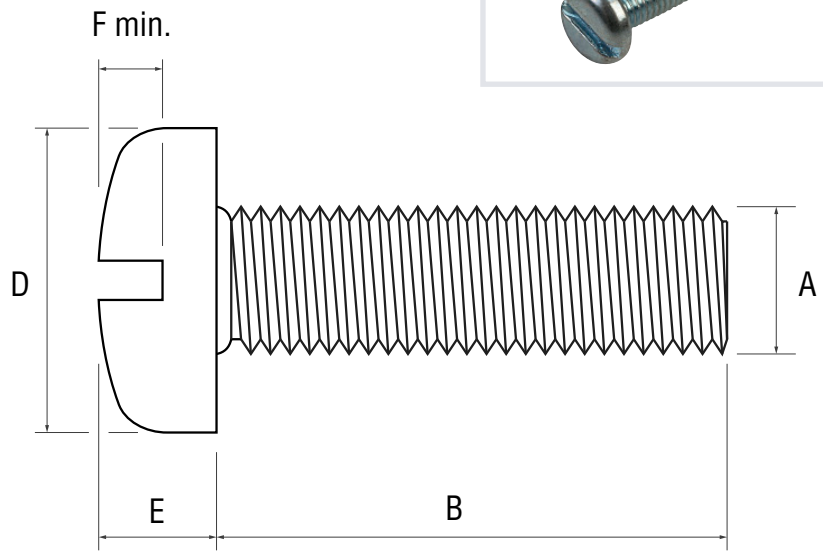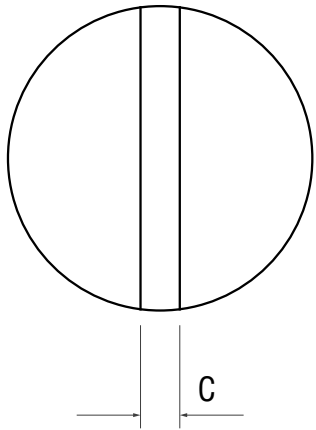



PART NUMBER TABLE

Part number	A Thread size	B Length	C Slot thickness	D Head width	E Head depth	F Slot depth	UNSPSC	EAN	Country of Origin
33-7007	M2.5	6	0.6	5.0	1.5	0.6 min.	73181900	5053556009206	China
33-7008		10					73181900	5053556009213	China
33-7009		12					73181900	5053556009220	China
33-7010		20					73181900	5053556009237	China
33-7011	M3	6	0.8	6.0	1.8	0.7 min.	73181900	5053556009244	China
33-7012		10					73181900	5053556009251	China
33-7013		12					73181900	5053556009268	China
33-7014		16					73181900	5053556009275	China
33-7015		20					73181900	5053556009282	China
33-7016		25					73181900	5053556009299	China
33-7017	M4	6	1.2	8.0	2.4	1 min.	73181900	5053556009305	China
33-7018		10					73181900	5053556009312	China
33-7019		12					73181900	5053556009329	China
33-7020		16					73181900	5053556009336	China
33-7021		20					73181900	5053556009343	China
33-7022		25					73181900	5053556009350	China
33-7023		30					73181900	5053556009367	China
33-7024	M5	6	1.2	10.0	3.0	1.2 min.	73181900	5053556009374	China
33-7025		12					73181900	5053556009381	China
33-7026		16					73181900	5053556009398	China
33-7027		25					73181900	5053556009404	China

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact, telephone our main office on **01206 838000** or email **Sales@Rapidonline.com**.



Important Notice: This data sheet and its contents (the "Information") belong to Rapid Electronics Limited or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but Rapid Electronics Limited assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where Rapid Electronics Limited were aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict Rapid Electronics Limited's liability for death or personal injury resulting from its negligence.